


Proposed Temperature profile for OEP8000

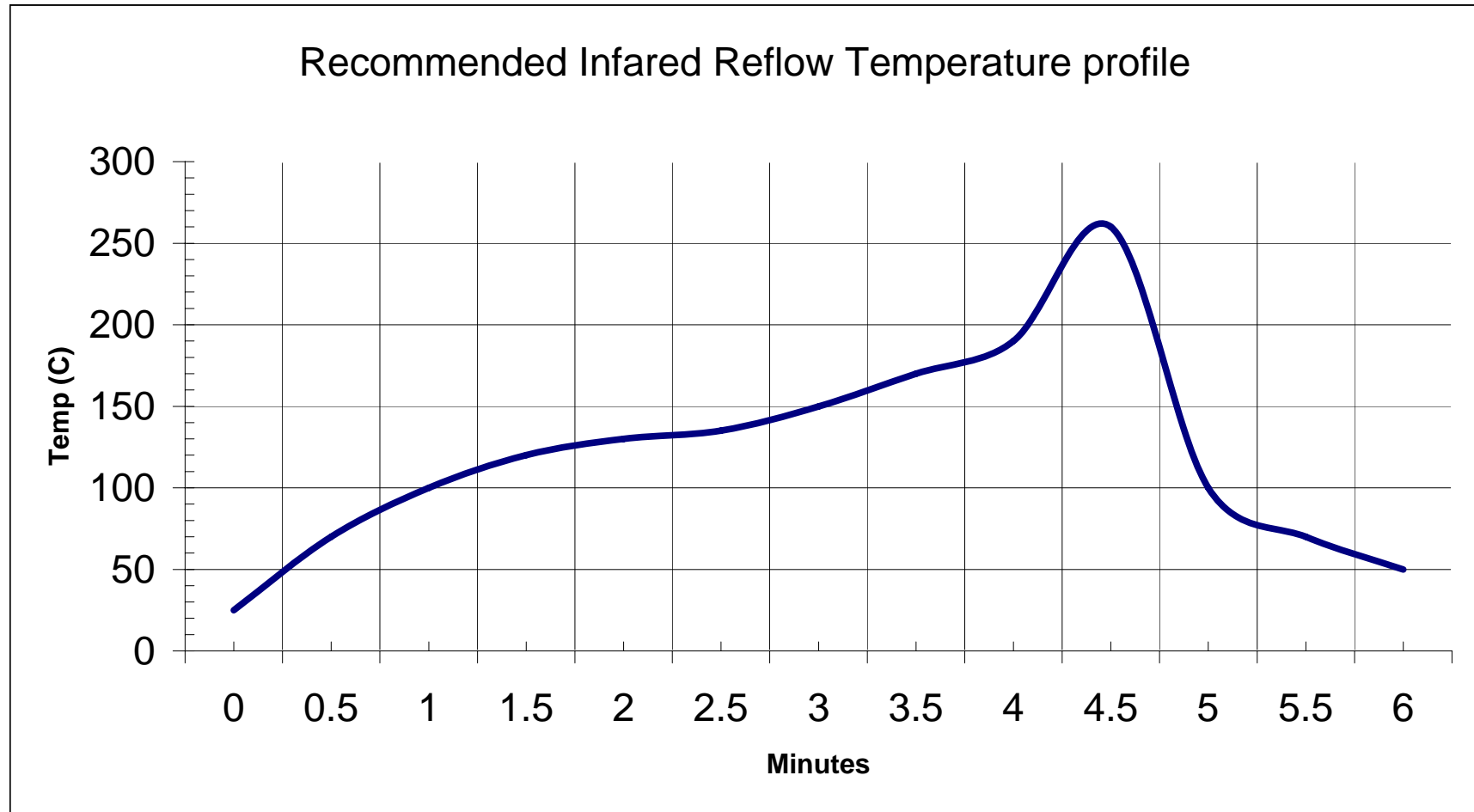

Note Maximum Temperature (260°C) shall not exceed 10 Seconds
 Maximum Duration above 183°C shall not exceed 90 Seconds

Recommended Infrared Reflow Temperature profile

0	25
0.5	70
1	100
1.5	120
2	130
2.5	135
3	150
3.5	170
4	190
4.5	260
5	100
5.5	70
6	50