


Datasheet

2m 8-Way Male Moulded Plug to Free End DIN Cable Assembly

RS Stock number 463-518



Dimensions: (mm)

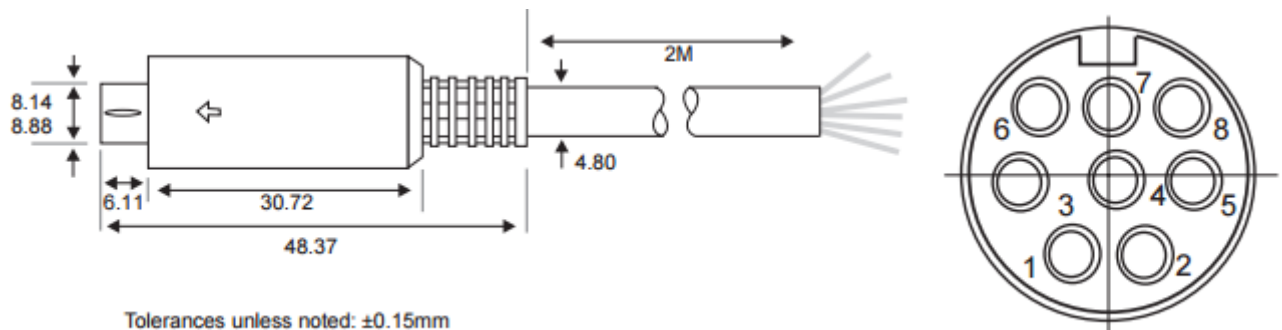

Specifications

| | |
|------------------------|--------------------|
| Temperature range: | -25°C to +85°C |
| Applicable wires: | AWG 26 to 30 |
| Current rating: | 1A AC/DC |
| Insulation resistance: | 50MΩ min. |
| Voltage rating: | 50V AC/DC |
| Withstanding voltage: | 500V AC for 1 min. |

Material/Finish

| | |
|-------------------|---|
| Metal shell: | Brass |
| Contacts: | Solder bucket |
| Contact material: | Plug-Brass, Receptacle-Phosphor/Bronze |
| Contact plating: | Pb/Sn, Tin or Au/Nickel |
| Mould-in cover: | Tinned/Brass |
| Insulator: | PBT or Nylon +30% Fibre reinforced (UL94V-0) |
| Cable colour: | Black |