

## Model No. 6230

2-1/2in (64mm) Wide ProSeries® Solid Steel  
Rekeyable Pin Tumbler Padlock

### Best Used For:



Security Gates &  
Fences



Trailers, Trucks, &  
Towing



Trailers, Vans &  
Moving Trucks



Truck Doors

## Overview & Features

## Product Features


- ProSeries® Padlocks are designed for Commercial/Industrial applications
- 2-1/2in (64mm) round wide solid steel body
- Chrome rustproofing provides longer life
- 1-1/8in (29mm) tall, 7/16in (11mm) hardened boron alloy shackle for superior cut resistance
- Dual ball bearing locking mechanism resists pulling and prying
- High security, rekeyable 5-pin cylinder with spool pins is virtually impossible to pick

## Product Details

The Master Lock No. 6230 ProSeries® Solid Body Padlock features a 2-1/2in (64mm) round wide solid steel body and a 1-1/8in (29mm) tall, 7/16in (11mm) diameter hardened boron alloy shackle for superior cut resistance. Chrome rustproofing provides longer life and a dual ball bearing locking mechanism resists pulling and prying. Ideal for industrial and construction applications, the high security, rekeyable 5-pin cylinder with spool pins is virtually impossible to pick.

Product Specifications

Product Number	6230
Body Width	64mm
Shackle Dimensions	A: 11 mm B: 29 mm C: 22 mm
Colour	Silver
Description	Keyed Different, Commercial Boxed Packaging
Shelf Pack Qty	6
Master Carton Qty	24

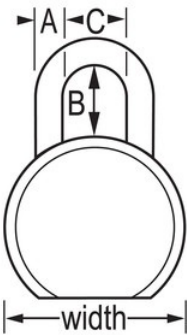

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France  
O:+33-1-41437200 | F:+33-1-41437204  
[www.masterlock.eu](http://www.masterlock.eu)