

ABT-443-RC SURFACE MOUNT TRANSDUCER

SOUNDERS & BUZZERS

Specifications

ABT-443-RC


Rated voltage	3.6Vp-p
Operating voltage	2.5~4.5Vp-p
Rated current at rated voltage	≤90mA
Sound output at 2730Hz at 10cm at rated voltage	≥85dB
Resonant frequency	2730Hz
Coil resistance	16±3Ω
Operating temperature	-30~+80°C
Storage temperature	-40~+85°C
Weight	0.5g

Requires additional electronic circuitry to operate as a sounder

Features

- ROHS compliant
- Black in colour
- Very small and low profile
- Surface mount
- Housing material: LCP

All data at 25°C unless otherwise specified

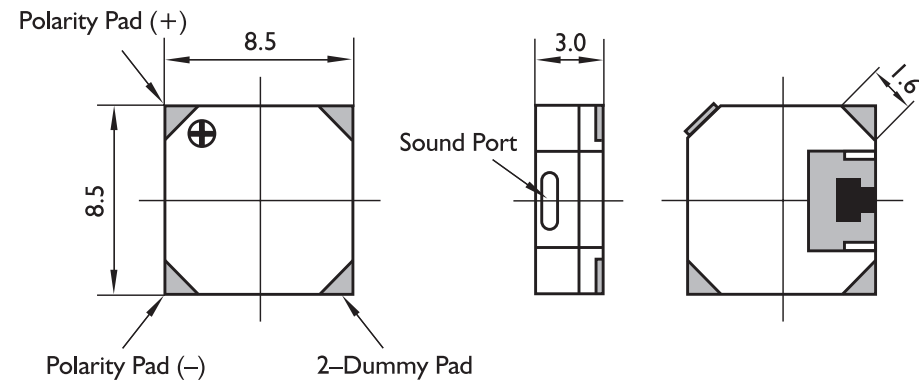

Dimensions Unit: mm Tolerance: ±0.5mm




ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.uk

www.abcomponents.co.uk

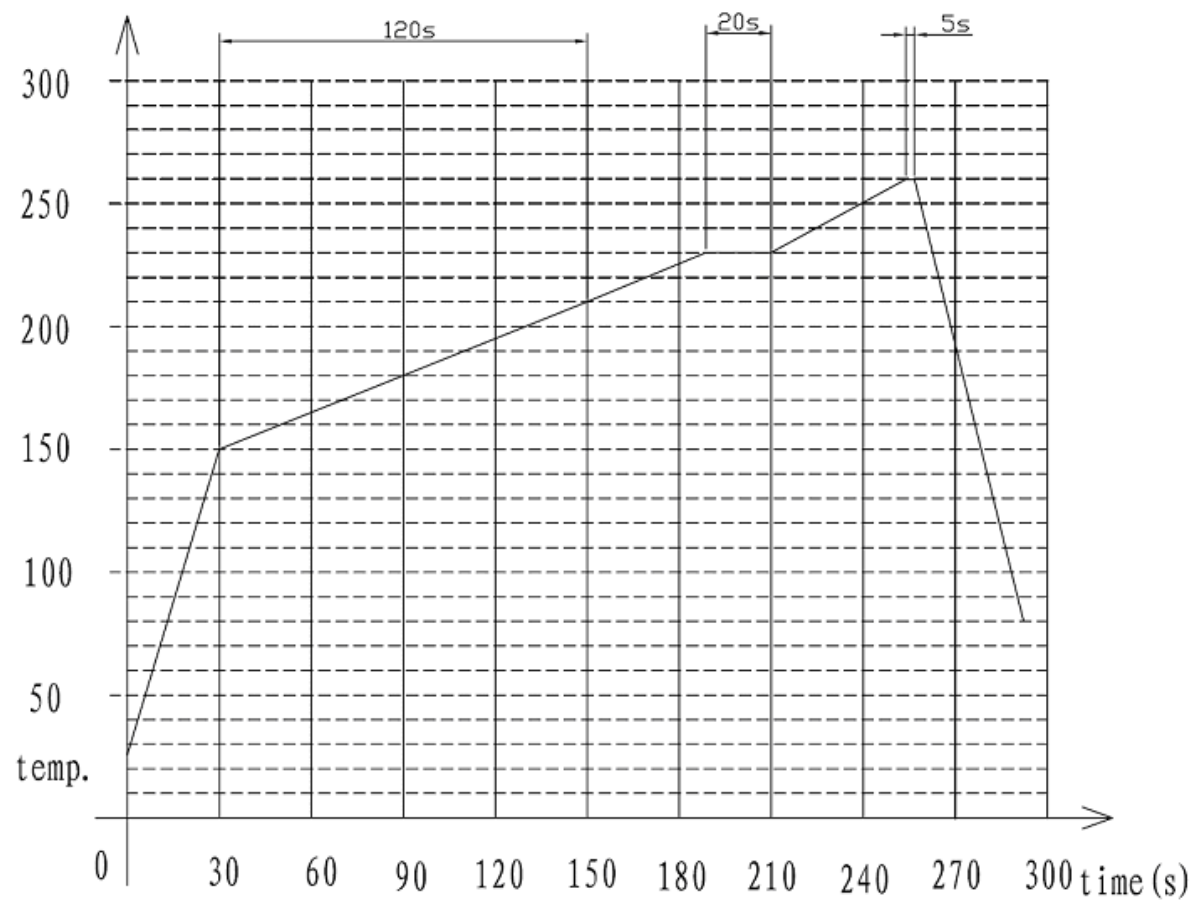

ALAN BUTCHER COMPONENTS LTD

Alan Butcher Components Ltd

Unit 1 Beechwood Clump Farm Industrial Estate Tin Pot Lane Blandford Dorset DT11 7TD

Telephone 01258 456360 Facsimile 01258 459194 Email sales@abcomponents.co.ukwww.abcomponents.co.uk