




ENGLISH

Datasheet

## RS Pro Steel Alloy Compression Spring, 35.5mm x 4.4mm, 0.22N/mm

RS Stock No: **751-427**

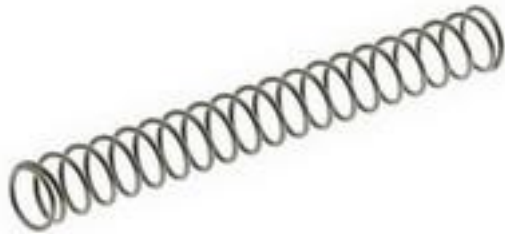

### Product Details

RS Pro stainless steel alloy compression spring measures 35.5 x 4.4 mm and has a spring rate of 0.22 N/mm. It handles a load of 5.25 N at a minimum working length of 11.4 mm. This spring features right hand helix construction.

### Features and Benefits

- Wire diameter ends up to 0.8 mm are squared and ungrounded
- Wire diameter ends 1 mm and over are squared and ground
- Manufactured with a right hand helix

**Specifications:**

Ends	Closed (Square)/Unground
Material	Steel Alloy
Free Length	35.5 mm
Load at Minimum Working Length	5.25 N
Minimum Working Length	11.4 mm
Outside Diameter	4.4 mm
Spring Rate	0.22 N/mm
Wire Diameter	0.4 mm