


Data sheet



Safety / Valiance RCD Protection

RCD07MAVN – Valiance RCD Double Metal Socket - Active

Product Image & Line Diagram

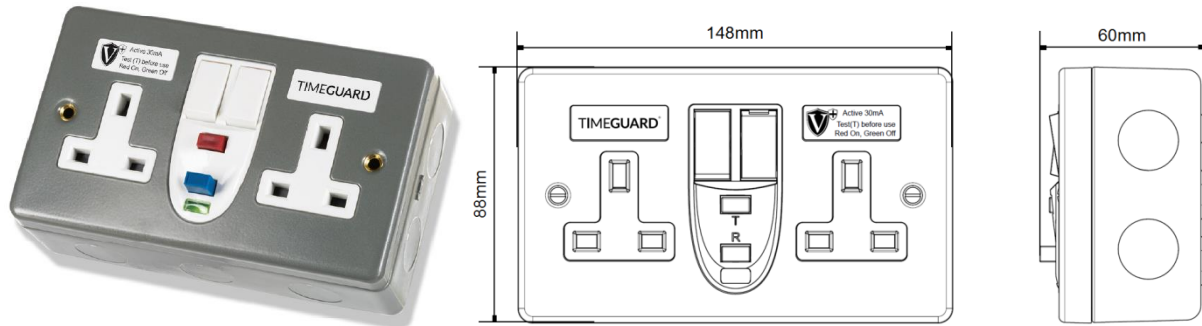

Technical Data

General	
Operating Voltage	230V AC
Frequency	50Hz
Installation Type	Surface or Recessed
Class Protection	Class 1
Accessories (Included)	Instructions, Fixing Screws x 2
Operating Temperature	-5° to +40°C
Dimensions	Height 88mm, Width 148mm, Depth 60mm
Weight	513g
Fixed Cable Capacity	1x8mm ² or 2x4mm ² or 3x2.5mm ²
Flexible Cable Capacity	10.5mm Diameter maximum
Altitude	<2000m
EAN	5012483014561
Designed In Accordance To	BS 7288, BS 1363:2 Includes updates & amendments
Guarantee Period	3 Years
Switched Socket	
Socket Outlet	Twin gang 13A BS Plug
Switch Type	Single Pole
RCD Protection	
Classification	Non-Latching (Active)
RCD Type	Double Pole, Suitable for 2 and 3 wire applications
Rated Trip Current	30mA
Breaking Capacity	250A (Earth leakage)
Trip Speed	Less than 40msec at 150mA residual current
Through Fault Withstand	1500A
Construction	
Body	Steel
Cable Entry's	Multiple M20 knock-outs



A theben Group Company

Article Number: RCD07MAVN DS120319V1



Timeguard Ltd reserves the right to withdraw, improve or modify any design without prior notification. Timeguard Ltd cannot be held responsible for the incorrect application of any product.

Additional information can be found at: www.timeguard.com