


LEITZ

## Leitz IQ OptiMax Office Micro Cut Paper Shredder Security P5 35L - White



The Leitz IQ OptiMax office shredder provides an innovative and stylish shredding solution, whilst ensuring exceptional document security and peace of mind. This high-security DIN P5 paper shredder effortlessly shreds up to 10x A4 sheets at a time into micro-cut pieces. IQ OptiMax features unique Bin Rotation Technology (BRT), effectively maximizing capacity by +33%\*. The rotating bin ensures flat and even paper distribution to eliminate paper shreds from forming a peak in the bin; allowing an additional 140x A4 sheets to be shredded before it requires emptying. BRT means there's no need to remove or shake the bin; the 'bin full' indicator activates only when it reaches 100% capacity. The generous 35L bin holds up to 550 x A4 sheets and illuminates blue during use for the ultimate shredding experience. The intuitive LED rotating display includes red warning indications for various states such as bin full and door open. Leitz IQ OptiMax is versatile for any workplace environment due to its ultra-quiet operation, sleek design and impressive durability. Continuous runtime of 120 minutes. White colour.

\*Leitz IQ OptiMax tested with and without bin rotation technology.

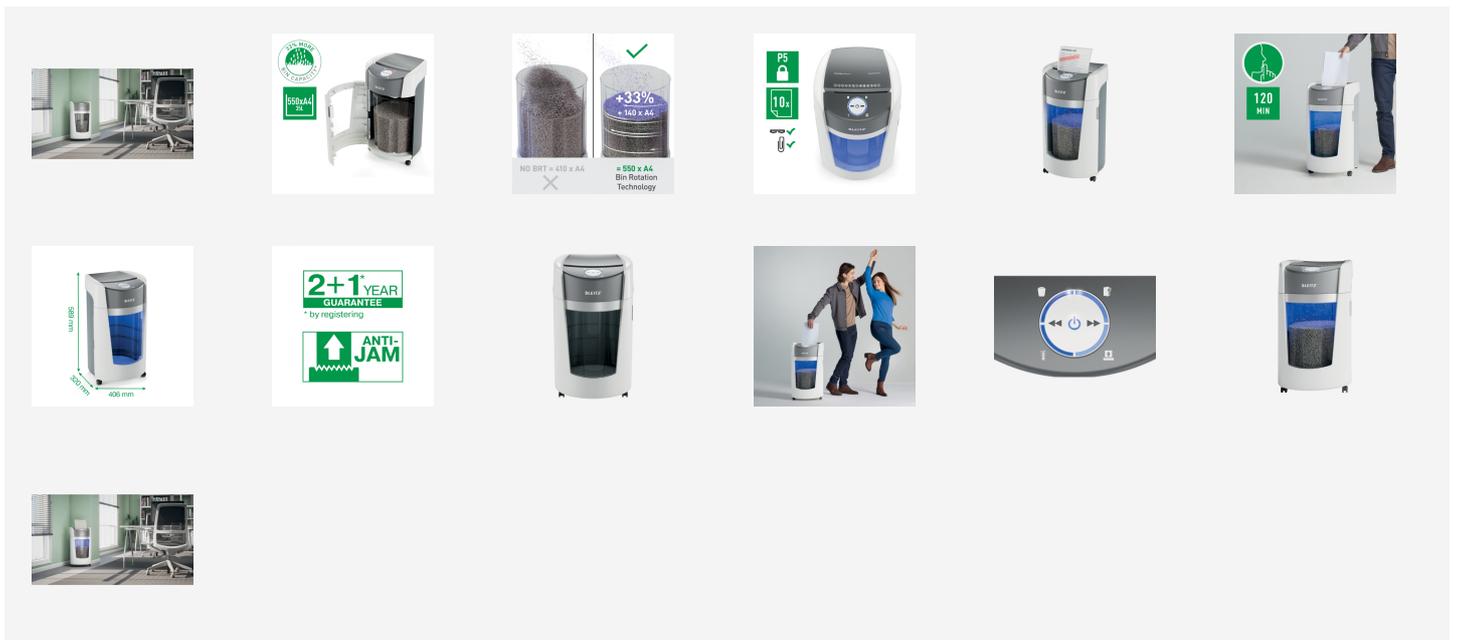

## Attributes

- Shreds up to 10x sheets of A4 paper (80gsm) in just 10 seconds, into high security P5 micro cut pieces.
- Unique Bin Rotation Technology (BRT) maximizes bin capacity +33%\* and significantly reduces mess when emptying. \*Leitz IQ OptiMax tested with and without bin rotation technology.
- Generous 35L bin capacity holds up to 550x A4 sheets before it needs to be emptied; +33% more capacity compared to no BRT (+140 x A4 sheets).
- Dynamic LED rotating display with warning indications for bin full, door open, overheat and overload.
- Ultra quiet operation - for a calm working environment (when using Leitz oil papers regularly)
- Shreds staples and paper clips, no need to remove them first.
- Continuous 2 hours / 120 min run time - complete uninterrupted shredding ideal for office use.
- Anti-jam technology means that the shredder automatically stops and reverses the paper out when too much paper is inserted.
- The shredder machine has a circular design, allowing it to easily fit into tight areas for space optimisation.
- Easy to move across locations thanks to four high quality castor wheels.
- 2+1 years guarantee - register to get your extra year



## Specifications

Number	83601000
Colour	White
Dimensions (W x H x D)	380 x 710 x 380 mm
Cut Type	Micro Cut
Maximum Slot Entry Width (mm)	223
Run Time From Cold (min)	120
Run Time/Cool Down Time (min)	45
Shredded Particle Width mm	2x15
Security Level	P-5
Cutting Capacity sheets (80gsm paper)	10
Container/collection volume in l	35
Shreds	Staples and paper clips
Period of Warranty (Years)	2 + 1 year
*Location	Office
*Number Of Users	5-10
*Shredder Bin	Unique Filling Technology, Revolving, Bin Window, Backlit
*Shredder Features	Wheels, Touch Control, Jam Free Technology
Weight	15000 g
Pallet quantity	8
EAN code	4002432137701