


# Datasheet

## RS 8V Pk-Pk PCB Mount Magnetic Buzzer, 85dB

### Continuous

RS Stock 780-0740

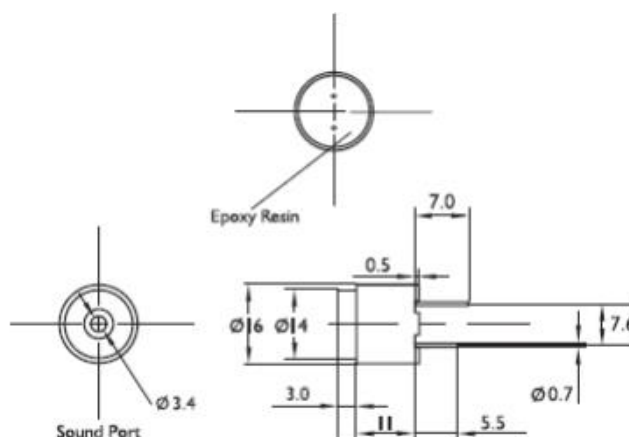

Dimensions: (mm)

### Features:

- PCB Mountable
- Sealed Base
- Wave Solderable and Washable

All data at 25°C unless otherwise specified.

SPECIFICATIONS	Electro Mechanical Transducer
Rated Voltage (Vp-p Square Wave)	6Vp-p
Operating Voltage	4-8Vp-p
Rated Current at rated voltage	≤40mA
Coil Resistance	50±5Ω
Sound Output at 2400Hz at 10cm, at rated voltage	≥85dB
Resonant Frequency	2400 ± 500Hz
Operating Temperature	-20 ~ +70°C
Storage Temperature	-30 ~ +80°C
Weight	2g
Tone	Continuous
Drive Type	External