

T 15/1 HEPA BP

Robust, compact and ergonomic: The T 15/1 Bp HEPA battery-powered dry vacuum cleaner is sustainably produced from 45% recycled material¹⁾ and impresses with its excellent suction power and HEPA 14 filter.



Made in Europe



Order no.

1.355-355.0

- 15-l container, made from 45% recycled material, quiet – 57 dB(A), ergonomic design
- 36 V cordless tool, HEPA-14 filter, ecoefficiency mode, accessory storage
- Floor nozzle 280 mm, aluminium telescopic suction tube, HEPA 14 filter, crevice nozzle, upholstery nozzle

Technical data

EAN code		4066529117878
Battery platform		36 V battery platform
Container capacity	l	15
Container material		Plastic with recycled material
Sound pressure level	dB(A)	57
Air flow	l/s	40
Nominal power	W	500
Vacuum	mbar / kPa	223 / 22
Number of batteries required	Piece(s)	1
Performance per battery charge	m²	approx. 150 (7.5 Ah) ecoefficiency mode: max. 66 (7.5 Ah) / Power mode: max. 31 (7.5 Ah) / ecoefficiency mode: max. 50 (6.0 Ah) / Power mode: max. 22 (6.0 Ah)
Run time per battery charge	min	58 / 81
Battery charging time with quick charger 80% / 100%	min	58 / 81
Charging current	A	6
Power supply for battery charger	V / Hz	100 – 240 / 50 – 60
Colour		anthracite
Weight without accessories	kg	7.1
Weight incl. packaging	kg	8.6
Dimensions (L × W × H)	mm	430 × 255 × 405

Scope of supply

Versions:	Battery and battery charger not included
Suction hose length:	2 m
Bend:	Antistatic with air-flow regulator
Telescopic suction tube:	615 – 1007 mm
Telescopic suction tube, material:	Aluminium
Switchable floor nozzle	
Upholstery nozzle	
Crevice nozzle	
Quantity of filter bags:	1 Piece(s)
Filter bag material:	Fleece
Motor protection filters	
HEPA filter type:	HEPA 14 filter
Permanent filter basket:	Fleece

Equipment

ecoefficiency mode	
Foldable Ergonomic carrying handle	
Integrated accessory storage	

® All plastic parts, excluding accessories.



Sustainable and robust: 45% recycled content

- Production: reduced use of raw materials and energy.
- Lower CO₂ emissions thanks to production from recycled material.



Ultra-efficient HEPA 14 filter

- For the highest safety standards at hygiene-sensitive sites.
- High filtration and separation degree: 99.995%.



eco!efficiency mode

- Sustainable thanks to reduced energy consumption.
- Reduces volume and noise pollution.
- Extends the battery runtime.

SUSTAINABILITY INFORMATION FROM T 15/1 HEPA BP
1.355-355.0



Certificates



Sustainability features

eco!Mode (energy saving mode)			
Recycled plastics share device	%	45	All plastic parts excluding accessories

EQUIPMENT FOR T 15/1 HEPA BP


1.355-355.0



		Order no.	Description	
FILTER T/ NT				
Main filter baskets				
Filtering basket complete, T 10/1, T 15/1, T 10/1 Bp, T 15/1 Bp	1	2.885-909.0	Robust and durable: permanent main filter basket made of non-woven material. The sustainable filter basket can be easily hand-washed at 30 °C and reused. Contents: 1 piece.	■
HEPA filter for dust class H				
Accessories filter Hepa T-range	2	2.889-424.0	Increases the filter capacity and improves the blower air: The highly effective HEPA 14 filter offers a separation degree of 99.995% and is certified according to test standard DIN EN 1822:2019.	■
Fabric filter bag				
Filter bag cloth	3	6.904-316.0	The fabric filter bag for Kärcher dry vacuum cleaners is made of cotton and can be washed at up to 40 °C.	□
Exhaust air filter				
Filter motor protecting, 3 Piece(s), T 10/1 Bp, T 15/1 Bp, T 10/1, T 15/1	4	2.885-910.0	The fleece filter reliably protects the motor from dirt and extends the lifetime of your dry vacuum cleaner or battery-powered dry vacuum cleaner. Contents: 3 pieces.	□
BENDS				
Plastic bend				
Elbow electrically conducting packaged N	5	2.889-148.0	Antistatic, ergonomic bends with air-flow regulator in size DN 35 for dry vacuum cleaners. Equipped with a clip 2.0 connection at the hose end and a cone connection at the accessory end.	■
SUCTION NOZZLES				
All-purpose nozzles (wet/dry)				
Combination nozzle RD 270+	6	2.860-278.0	Switchable plastic floor nozzle with width of 280 mm and nominal size of DN 35 for cleaning textile and hard surfaces. Features a practical parking hook.	■
Parquet nozzle packaged D360 NW35	7	2.889-196.0	Gentle cleaning of parquet floors, delicate wooden floors and other hard surfaces: plastic parquet nozzle with width of 360 mm and nominal size of DN 35. Includes practical parking hook.	□
Parquet nozzle packaged D300 NW35	8	2.889-197.0	Plastic parquet nozzle with width of 300 mm width and nominal size of DN 35 for gentle cleaning of parquet floors, delicate wooden floors and other hard surfaces. Includes practical parking hook.	□
Floor tool packaged	9	2.889-360.0	High-quality plastic floor nozzle in nominal size of DN 35 for cleaning textile and hard floors. With a practical parking hook. Width: 290 mm.	□
Crevice nozzles				
Crevice nozzle packaged NW35	10	2.889-130.0	With the DN 35 plastic crevice nozzle, corners and crevices can be vacuumed quickly and thoroughly. Length: 210 mm.	■
Upholstery nozzles				
Upholstery nozzle complete NW35	11	6.905-998.3	Practical plastic upholstery nozzle in DN 35. Ideal for gentle cleaning of upholstered furniture such as sofas, armchairs, upholstered chairs and beds.	■
Suction brushes				
Suction brush packaged NW 35	12	2.889-221.0	Suction brush DN 35 with horsehair natural bristles.	□
Turbo nozzle				
Floor tool TURBO DN 35/32	13	2.860-277.0	Plastic turbo floor nozzle in nominal size of DN 35/32 for cleaning textile and hard floors. With a practical parking hook and DN 35/32 reduction bushing, 270 mm wide.	□
Upholstery nozzle TURBO	14	2.860-113.0	Plastic turbo upholstery nozzle (DN 35/32, 160 mm) with reduction sleeve.	□

■ Included in delivery. □ Available accessories.

EQUIPMENT FOR T 15/1 HEPA BP 1.355-355.0

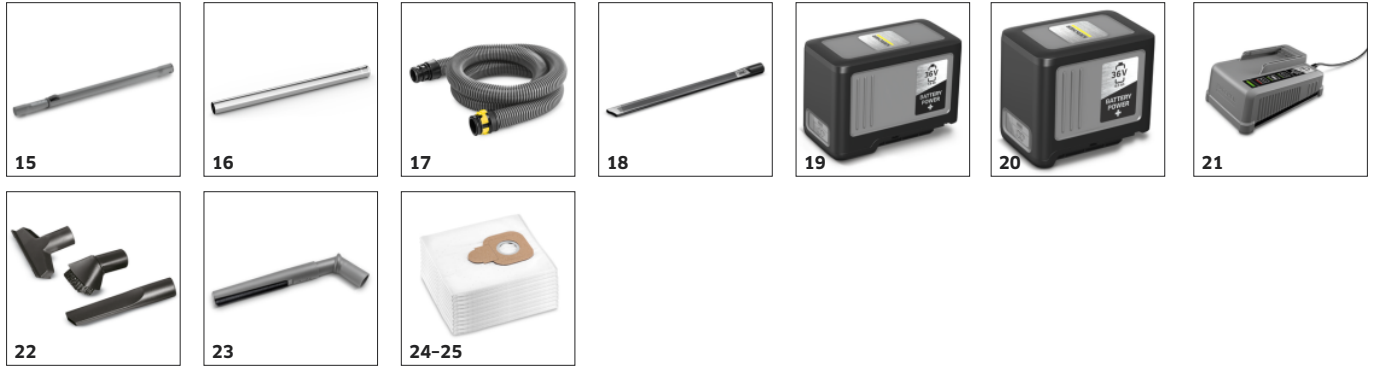

		Order no.	Description	
SUCTION TUBES				
Suction tubes metal				
Telescopic suction tube alu packaged DN3	15	2.862-011.0	Practical and extremely lightweight telescopic suction tube made of aluminium, painted basalt grey, for Kärcher dry vacuum cleaners. Nominal width DN 35 and 615-1007 mm long.	■
Suction tube chromed NW35 - 505mm	16	6.902-074.0	Chrome-plated steel suction tube for Kärcher dry vacuum cleaners and wet and dry vacuum cleaners, nominal width DN 35 and 505 mm long.	□
SUCTION HOSES				
Suction hoses with clip system 2.0 (compatible with vacuum cleaners from model year 2017 on)				
Suction hose	17	2.889-161.0	The suction hose in nominal width DN 35 and with 2 m length is suitable for use with dry vacuum cleaners from Kärcher.	■
VACUUMS				
Nozzles				
Flexible Crevice Nozzle	18	2.863-374.0	Flexible crevice nozzle for cleaning hard-to-reach areas in the home, basement, workshop, car, etc. with Home & Garden wet and dry vacuum cleaners and spray extraction cleaners.	□
BATTERIES				
Battery Power+ 36/75	19	2.445-043.0	A capacity of 7.5 Ah guarantees long runtimes for the Battery Power+ 36 V lithium-ion battery. Very powerful, with Real Time Technology via LCD display and protection against overcurrent.	□
Battery Power+ 36/60	20	2.042-022.0	Extremely powerful Battery Power+ 36 V lithium-ion battery with a capacity of 6.0 Ah for a long runtime. With innovative Real Time Technology via LCD display and voltage monitoring.	□
BATTERY CHARGERS				
Fast battery recharger Battery Power+ 36/60	21	2.445-047.0	Charge all 36 V Kärcher Battery Power and Kärcher Battery Power+ lithium-ion batteries with max. 6 A charging current: Quick charger with LED operating status indicator. Easy wall mounting.	□
NOZZLE SETS				
Nozzle kit: crevice nozzle, upholstery nozzle, suction brush, ID 35	22	2.860-116.0	Nozzle kit consisting of a crevice nozzle, upholstery nozzle and suction brush. The nozzle kit is suitable for all Kärcher dry vacuum cleaners and wet and dry vacuum cleaners in nominal width DN 35.	□
FURTHER ACCESSORIES DRY VACUUM CLEANERS				
Set hand nozzle	23	2.889-361.0	Innovative surface nozzle with nominal width DN 35 for dry vacuum cleaners from Kärcher. The nozzle can be used on both hard and carpeted surfaces. Working width: 180 mm.	□
FILTER BAGS				
Fleece filter bags (3 ply)				
Filter bag fleece, 10 Piece(s), T 10/1, T 10/1 Bp, T 15/1, T 15/1 Bp	24	2.885-908.0	Tear-resistant 3-layer fleece filter bags, dust class M, suitable for Kärcher dry vacuum cleaners. Contents: 10 pieces.	□
Filter Bag Bulk Package Fleece, 200 Piece(s), T 10/1, T 15/1	25	2.885-926.0	Tear-resistant 3-layer fleece filter bags of dust class M, suitable for Kärcher dry vacuum cleaners. Contents: 200-pack.	□

■ Included in delivery. □ Available accessories.