



**POWER  
AT WORK**

# Technical Specification

## 25m Open Reel

### OMG25164SL-PX




### Features

- » Robust case reel, with four shuttered sockets
- » Safety thermal cut-out
- » Power on/off switch
- » Power LED indicator
- » Easy wind handle
- » Compatible with wall mount bracket

### Description

Lightweight and sturdy, this portable open reel with 25 metres of cable is designed for home, garden and heavy duty applications. Designed and engineered for longevity, the plastic drum provides reliable protection when in use, transported or stored. This cable reel provides four shuttered Schuko sockets, power switch, LED indicator, highly visible green cable and has a built-in safety thermal cut-out for protection against overloading when fully reeled.

### Line Diagrams

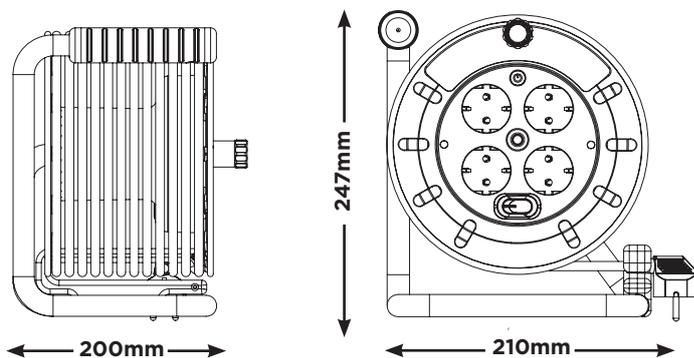

### Technical Specifications

<b>Standards</b>	EN 61242
<b>Maximum connected load</b>	1000W / 230V - When fully wound 3000W / 230V - When fully unwound
<b>Switch</b>	Two-pole
<b>Cable length</b>	25m
<b>Cable diameter</b>	1.5 mm <sup>2</sup> (H05VV-F)



## Product Information

<b>Part No</b>	OMG25164SL-PX	<b>Qty</b>	2
<b>Type</b>	Open Cable Reel	<b>Shipping Carton Info (m)</b>	H:0.28 x W:0.24 x D:0.45
<b>Cable Type</b>	PVC	<b>CBM (m<sup>3</sup>)</b>	0.03024
<b>Weight (kg)</b>	3.3	<b>G.W. (kg)</b>	7.5
<b>Amp</b>	13A	<b>EAN Barcode</b>	5015056523408
<b>Product Dimensions (cm)</b>	H:24.7 x W:22 x D:20	<b>ITF Barcode</b>	5015056523446



**POWER  
AT WORK**