

## Open core connector crimping pliers

### 985757 Open core connector crimping pliers





#### DIN 46249

- Die with 3 cavities for open core terminals with 1.5; 2.5 and 6 mm<sup>2</sup> section.
- Capacity 1.5 to 6 mm<sup>2</sup>.
- Length: 195 mm.
- Weight: 250 g.

## Wire end crimping pliers


### 985895 Wire end crimping pliers

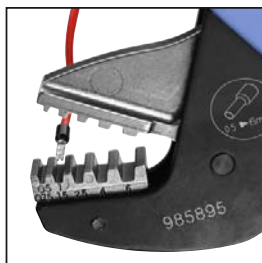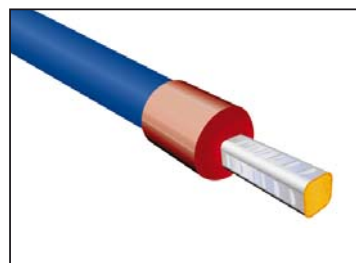

#### NFC 63-023

- Stainless steel 5-cavity dies:
  - 0.5 to 0.75 mm<sup>2</sup>.
  - 1 to 1.5 mm<sup>2</sup>.
  - 2.5 mm<sup>2</sup>.
  - 4 mm<sup>2</sup>.
  - 6 mm<sup>2</sup>.
- Unlocking accessible at all times.
- Reversed crimping: terminal positioned on the fixed part for more effectiveness and precision.
- Capacity 0.5 to 6 mm<sup>2</sup>.
- Shape allowing hand setting.
- Soft touch.
- Length: 230 mm.
- Weight: 490 g.

### 985898 Auto-adjustable wire end crimping pliers

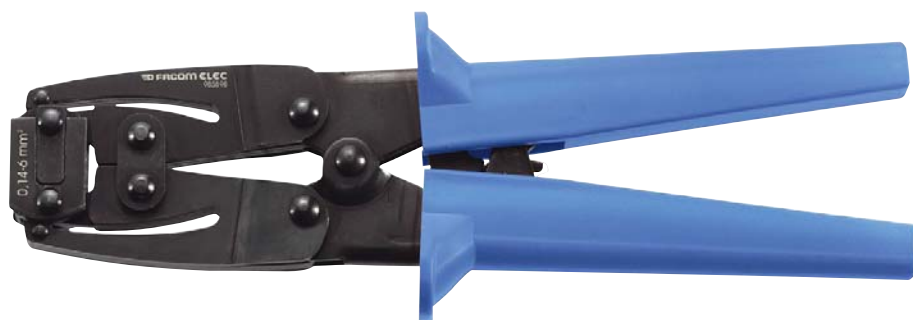

#### NFC 63-023

- Allows to use the same cavity to crimp terminations from 0.14 to 6 mm<sup>2</sup> with or without insulation.
- With ratchet system guaranteeing proper crimping.
- Easy unlocking in case of mishandling.
- Comfort grip.
- Length: 210 mm.
- Weight: 500 g.

