

## RS PRO SY11 In-Line Cable Mount Connector

RS Stock No.:

0304356
---------

0304357
---------

0304358
---------

0304360
---------

### Features

- Bayonet Coupling
- IP67
- 2-5 Poles
- Plug & Socket Set
- Cable to Cable Connections



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding. Making RS PRO the Smart Choice for our customers.





### Product Description

The RS Pro SY11 series is a range of lightweight but robust waterproof connectors, which are sealed to IP67. Bayonet style coupling ensures a secure connection, even in the harshest environments. Plugs and receptacles are available with either male pins or female sockets. These products are ideal for use in outdoor applications where a secure, waterproof connection is required. Updated shell offering an improved seal, which increases reliability and durability.

## General Specifications

Housing Material	PC, Nylon66, Fire Resistance: V-0
Size	SY11
Cable outer diameter range	4-6.5mm
Body Orientation	Straight
Colour	Black
Temperature Range	-40~ +85°C
Mounting Type	In-Line Cable Mount
Mating Cycle	500
Application	Outdoor Lighting, LED Screens, Outdoor Security Cameras, and Industrial Control Systems.

## Solder Contact Options

Number of contact	2	3	4	5
Male contact face view				

## Electrical Specifications

# SY11 In-Line Cable Mount Connector




RS Article Number (Set)	0304356		0304357	
RS Article Number (Individual)	SY1110/P2II-C-B-NP	SY1111C/S2II-C-B-NP	SY1110/P3II-C-B-NP	SY1111C/S3II-C-B-NP
Specification	2 Pin	2 Pin	3 Pin	3 Pin
Rated Current (A)	5	5	5	5
Contact Diameter (Ø mm)	1	1	1	1
Rated Voltage (AC.V)	180	180	180	180
Test Voltage (AV.V) 1 min	1000	1000	1000	1000
Contact Resistance (m Ω)	5	5	5	5
Wire Size (mm <sup>2</sup> / AWG)	≤0.75/18	≤0.75/18	≤0.75/18	≤0.75/18
Contact Gender	Male	Female	Male	Female
Shell Type	Plug	Receptacle	Plug	Receptacle
Termination	Solder	Solder	Solder	Solder

RS Article Number (Set)	0304358		0304360	
RS Article Number (Individual)	SY1110/P4II-C-B-NP	SY1111C/S4II-C-B-NP	SY1110/P5II-C-B-NP	SY1111C/S5II-C-B-NP
Specification	4 Pin	4 Pin	5 Pin	5 Pin
Rated Current (A)	3	3	3	3
Contact Diameter (Ø mm)	0.7	0.7	0.7	0.7
Rated Voltage (AC.V)	125	125	125	125
Test Voltage (AV.V) 1 min	1000	1000	1000	1000
Contact Resistance (m Ω)	10	10	10	10
Wire Size (mm <sup>2</sup> / AWG)	≤0.5/20	≤0.5/20	≤0.5/20	≤0.5/20
Contact Gender	Male	Female	Male	Female
Shell Type	Plug	Receptacle	Plug	Receptacle
Termination	Solder	Solder	Solder	Solder

**Protection Category**

IP Rating	IP67
-----------	------

## Dimensional Line Drawings

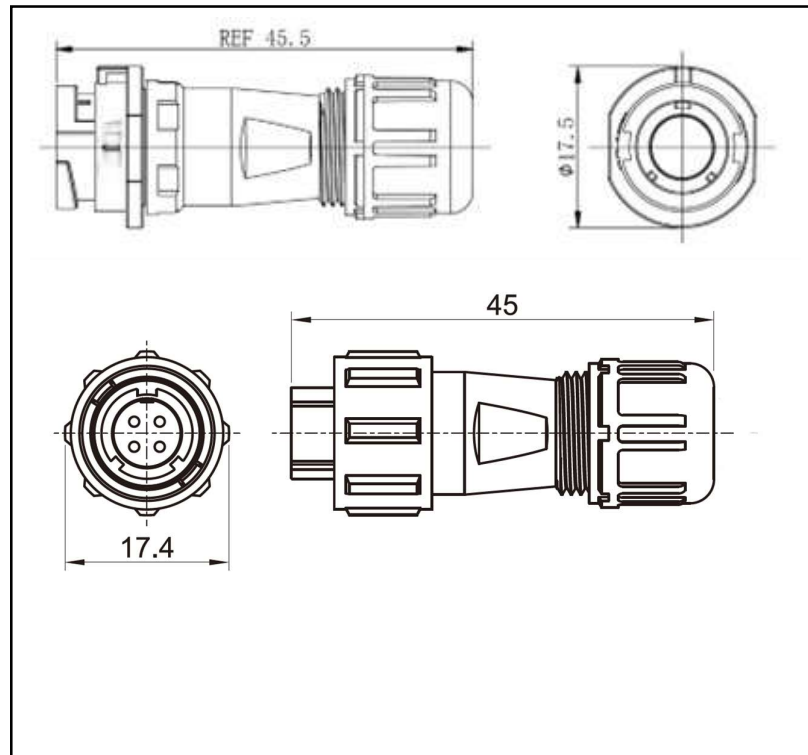

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories