



WG602

54 Mbps* Wireless Access Point

- *Help is there when you need it! NETGEAR provides, 24x7 technical support* in English, with selected local language support during office hours.*



Up to 5x Faster and Backward Compatible with 802.11b Wireless Networks

NETGEAR's WG602 Wireless Access Point lets you add IEEE 802.11g wireless access to your network. With its high-speed data transmission of up to 54 Mbps network users can share a broadband Internet connection, access e-mail, download large files, videoconference, and distribute and play digital images, videos, and MP3 files. Easy to set up and use, NETGEAR's Smart Wizard install assistant makes installations a cinch. And with Wi-Fi Protected Access (WPA-PSK) security, you can rest assured that your wireless network communications are private.

High-speed Simultaneously supports both IEEE 802.11b and 802.11g standard devices and networks. This dual mode capability protects your 802.11b wireless investment and, at the same time, has you ready for the up to five times faster 802.11g. Provides connectivity to a wired or wireless network for expanded bandwidth. Higher speeds expedite large file downloads and facilitate videoconferencing and the distribution and playing of high-quality multimedia content.

Secure Provides the highest available level of industry-standard WEP encryption: 128-bit for both 802.11b and 802.11g devices. MAC address authentication offers enhanced security by ensuring only authorized users can access the network. Wi-Fi Protected Access using a pre-shared key (WPA-PSK) is also supported.**

Dependable Connect two LANS wirelessly using the bridge mode. Extend your wireless signal by adding a WG602 in repeater mode.** Dynamic rate shifting according to environmental conditions achieves the fastest possible connections. Thorough testing ensures quality and reliable operation, which NETGEAR backs up with a solid 3-year warranty.

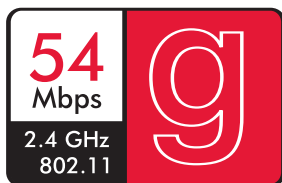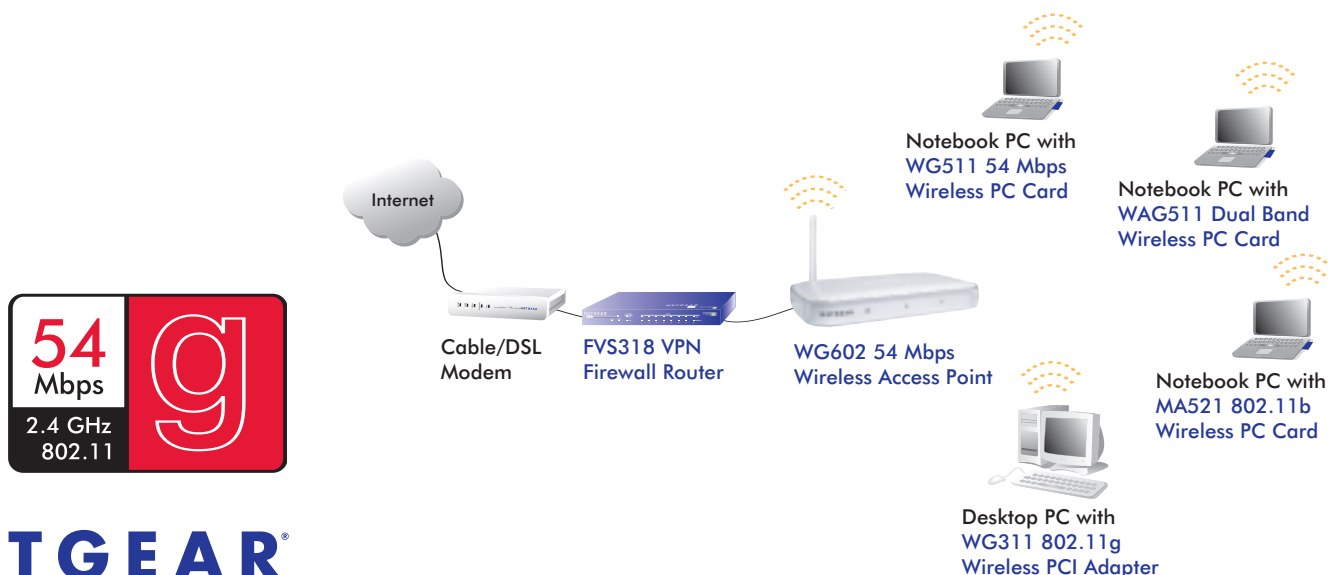

NETGEAR®

Everybody's connecting.™

Technical Specifications

802.11b/g

- **Radio Data Rate:**
 - 1, 2, 5.5, 6, 9, 11, 12, 18, 24, 36, 48 & 54 Mbps
- **Modulation Type:**
 - OFDM with BPSK, QPSK, 16QAM, 64QAM, DBPSK, DQPSK, CCK
- **Frequency:**
 - 2.412 ~ 2.462 GHz (US)
 - 2.412 ~ 2.484 GHz (Japan)
 - 2.412 ~ 2.472 GHz (Europe ETSI)
 - 2.457 ~ 2.462 GHz (Spain)
 - 2.457 ~ 2.472 GHz (France)
- **Antenna:**
 - Single detachable 2 dBi antenna
 - Transmit Power: 16 dBm
- **Security:**
 - 40-bit (also called 64-bit), 128-bit WEP encryption
 - MAC Address filtering
 - WPA-PSK**
 - 802.11i-ready

- **Features:**
 - Smart Wizard for easy installation
 - Firmware upgradable via a web browser
 - Backward compatible with existing IEEE 802.11b devices
 - SSID Broadcast enable/disable**
 - Supports bridging and repeater mode**

- **Power Adapter:**
 - 12 VDC, 1.2 A; plug is localized to country of sale

- **Physical Specifications:**
 - **Dimensions:** 28 x 175 x 118 mm (1.1 x 6.9 x 4.7 in.)
 - **Weight:** 0.3 kg (0.7 lb)

- **Electromagnetic Compliance:**
 - FCC Part 15 Sub Class B, CE

- **Environmental Specifications:**
 - Operating Temperature: 0 to 60° C (32 to 140° F)
 - Operating Humidity: 5-95% (noncondensing)

- **Warranty:**
 - NETGEAR 3-year warranty

Package Contents

- 54 Mbps Wireless Access Point WG602v3
- Power adapter
- Ethernet cable
- Resource CD
- User's guide
- Warranty/Support information card

Minimum System Requirements

- Pentium® Class PC
- Windows® 98SE, Me, 2000, or XP

NETGEAR Related Products

- WAG511 Dual Band 802.11a/b/g Wireless PC Card
- WAG311 Dual Band 802.11a/b/g Wireless PCI Adapter
- WG511 54 Mbps Wireless PC Card
- WG311 54 Mbps Wireless PCI Adapter
- WG111 54 Mbps Wireless USB 2.0 Adapter
- WGR614 54 Mbps Wireless Router
- WGE101 54 Mbps Wireless Ethernet Bridge
- FWG114P Wireless Firewall with USB Print Server

NETGEAR®

4500 Great America Parkway
Santa Clara, CA 95054 USA
Phone: 1-888-NETGEAR (638-4327)
E-mail: info@NETGEAR.com
www.NETGEAR.com

©2004 NETGEAR, Inc. NETGEAR®, the Netgear Logo, Auto Uplink, ProSafe, and Everybody's connecting are trademarks or registered trademarks of Netgear, Inc. in the United States and/or other countries. Microsoft, Windows, and the Windows logo are trademarks or registered trademarks of Microsoft Corporation in the United States and/or other countries. Other brand and product names are trademarks or registered trademarks of their respective holders. Information is subject to change without notice. All rights reserved.

* Free basic installation support provided for 90 days from date of purchase. Advanced product features and configurations are not included in free basic installation support; optional premium support available.

**Actual performance may vary due to operating conditions

D-WG602-5

CE0678①

FC Tested To Comply
With FCC Standards
FOR HOME OR OFFICE USE



* Actual results will vary depending upon operating environment.

** These features are only available on WG602v2 and v3.