



PW3 HI-VIS WORK TROUSERS

DESCRIPTION

Constructed using premium HiVisTex Pro tape and durable polyester/cotton fabric, this contemporary Hi-Vis Work Trousers provides ultimate wearer comfort. Oxford fabric reinforcement at key abrasion points and triple stitching throughout guarantees maximum durability. This trouser features top loading kneepad pockets and an easy access multiway thigh pocket for secure storage of your phone, keys and tools.

COMPOSITION

-  **Titanmill Plus: 65% Polyester, 35% Cotton, 300g**
-  **100% Polyester, 600D Oxford, PU Coated, 210g**
-  **Yellow/Black Short 28-42**

FEATURES

- Durable polycotton fabric with Texpel stain resistant finish
- Texpel™ Stain Eco a premium stain resistant finish to repel grime and water
- High rise back waistband ensures protection in all working positions
- Easy access cargo pocket
- Extendable leg length (31" to 33")
- Free pair of kneepads included with this trouser
- Triple-stitched seams for extra durability
- 2 Side pockets
- Two back patch pockets
- Double rule pocket
- D-ring for keys or ID cards
- Hammer loop for secure storage of work tools


STANDARDS

EN ISO 20471 Class 2
RIS 3279 TOM Issue 2 (Orange Only)
EN 14404: 2004 + A1: 2010 Type 2 Level 0 (When used in combination with S156)
ANSI/ISEA 107 SUPPLEMENTAL CLASS E

COLOUR / SIZES

SKU	COLOUR	SIZE RANGE
PW340YBS	YELLOW/BLACK	28-9

FEATURES

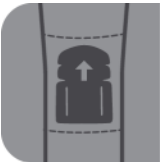

TOP-LOADING KNEE PAD POCKETS
Top-loading knee pad pockets for quick and easy access



HALF ELASTICATED WAIST
Half elasticated waist for a secure and comfortable fit



HEAT APPLIED SEGMENTED REFLECTIVE TAPE
This symbol indicates that the garment has heat applied reflective tape



STANDARDS



EN ISO 20471
High Visibility Clothing - Test Methods
And Requirements



PERFORMANCE WORKWEAR

PW3™ contemporary workwear blends sports and lifestyle trends with function, a modern fit and improved comfort.

GET THE COLLECTION



TECHINCAL INFORMATION



SATRA Technology Europe Ltd
(Notified Body Number.: NB: 2777) Bracetown
Business Park Clonee Dublin 15 D15 YN2P, Ireland
Cert No: 2777/14048-03/E00-00

· Wash garment inside out and fully fastened

Item	Colour Fit	Len (cm)	Wid (cm)	Hgt (cm)	Weight (Kg)	Cubic (m³)	EAN13	GTIN/DUN14
PW340YBS28	Yellow/Black Short	65	45	36	.929	5850.000	5036108313099	15036108801555
PW340YBS30	Yellow/Black Short	65	45	36	.968	5850.000	5036108313105	15036108801562
PW340YBS32	Yellow/Black Short	65	45	36	.979	5850.000	5036108313112	15036108801579
PW340YBS33	Yellow/Black Short						FALSE	
PW340YBS34	Yellow/Black Short	65	45	36	.995	5850.000	5036108313136	15036108801593
PW340YBS36	Yellow/Black Short	65	45	36	1.009	5850.000	5036108313143	15036108801609
PW340YBS38	Yellow/Black Short	65	45	36	1.027	5850.000	5036108313150	15036108801616
PW340YBS40	Yellow/Black Short	65	45	36	1.054	5850.000	5036108313167	15036108801623
PW340YBS41	Yellow/Black Short	65	45	36	1.069	5850.000	5036108313174	15036108801630
PW340YBS42	Yellow/Black Short	65	45	36	1.079	5850.000	5036108313181	15036108801647