



Socket

50

Product no. **03010028**
GTIN **4018754005369**
Model **50 28**



Label. 1/2 " Socket Size 28mm L.45mm

Properties.

- bi-hex with AS-Drive profile
- 1/2" internal square drive
- HPQ® high performance steel, chrome-plated
- DIN 3124 / ISO 2725-1 / DIN EN 3709 / ASME B 107.5 M


Technologies and features.



High Performance Quality (HPQ®)

Our HPQ® tool is made of wear-resistant high-performance steel, yet is thin-walled and lightweight. It withstands high torques and is ideal for work in confined spaces such as turbines.

Technical drawing.

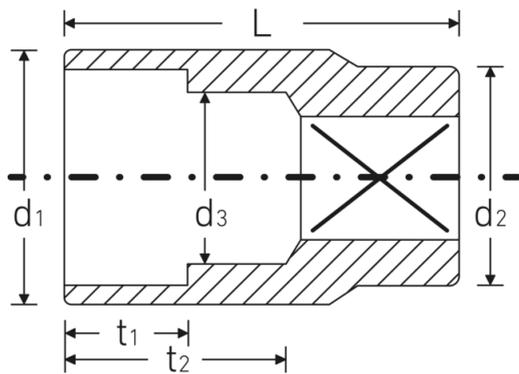

Technical attributes.

Drive profile	bi-hex AS-Drive
Square drive inner (inch)	1/2 "
d1	37,4 mm
d2	27 mm
d3	25 mm
DIN	DIN 3124 / ISO 2725-1, DIN EN 3709, ASME B 107.5 M
Length mm (L)	45 mm
Size [mm]	28 mm
t1	19,5 mm
t2	26,7 mm

Logistics data.

Depth mm (IFS)	45
Width mm (IFS)	38
Height mm (IFS)	38
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	190
Width (packaged, mm)	40
Height (packaging, mm)	47
Volume (packaged, dm ³)	0.3572 dm ³
Product no.	03010028
Weight (gross, kg)	0,790
Weight PAP (kg)	0,000
Weight PVC (kg)	0,008
GTIN	4018754005369
Country of origin AWR	GERMANY
Region of origin	Nordrhein-Westfalen
Customs tariff no.	82042000
Packing standard	5
Weight (g)	158 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
03010008	50 8	1/2 " Socket Size 8mm L.38mm	4018754005161
03010009	50 9	1/2 " Socket Size 9mm L.38mm	4018754005178
03010010	50 10	1/2 " Socket Size 10mm L.38mm	4018754005185

03010011	50 11	1/2 " Socket Size 11mm L.38mm	4018754005192
03010012	50 12	1/2 " Socket Size 12mm L.38mm	4018754005208
03010013	50 13	1/2 " Socket Size 13mm L.38mm	4018754005215
03010014	50 14	1/2 " Socket Size 14mm L.38mm	4018754005222
03010015	50 15	1/2 " Socket Size 15mm L.38mm	4018754005239
03010016	50 16	1/2 " Socket Size 16mm L.38mm	4018754005246
03010017	50 17	1/2 " Socket Size 17mm L.38mm	4018754005253
03010018	50 18	1/2 " Socket Size 18mm L.38mm	4018754005260
03010019	50 19	1/2 " Socket Size 19mm L.38mm	4018754005277
03010020	50 20	1/2 " Socket Size 20mm L.42mm	4018754005284
03010021	50 21	1/2 " Socket Size 21mm L.42mm	4018754005291
03010022	50 22	1/2 " Socket Size 22mm L.42mm	4018754005307
03010023	50 23	1/2 " Socket Size 23mm L.42mm	4018754005314
03010024	50 24	1/2 " Socket Size 24mm L.42mm	4018754005321
03010025	50 25	1/2 " Socket Size 25mm L.42mm	4018754005338
03010026	50 26	1/2 " Socket Size 26mm L.42mm	4018754005345
03010027	50 27	1/2 " Socket Size 27mm L.45mm	4018754005352
03010028	50 28	1/2 " Socket Size 28mm L.45mm	4018754005369
03010030	50 30	1/2 " Socket Size 30mm L.45mm	4018754005383
03010031	50 31	1/2 " Socket Size 31mm L.47mm	4018754149209
03010032	50 32	1/2 " Socket Size 32mm L.47mm	4018754005390
03010034	50 34	1/2 " Socket Size 34mm L.47mm	4018754005413
03010036	50 36	1/2 " Socket Size 36mm L.52mm	4018754283668

GTIN.



STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal