


Water-resistant pocket A5 with cable ties

Article number	505919	Sales unit quantity	1 Bag
Colour	Transparent	Sales unit EAN	4005546742090
Packaging unit	5 pieces / bag	Packing weight (gross)	301.2 G
Base EAN	4005546742090	Country of origin	PL

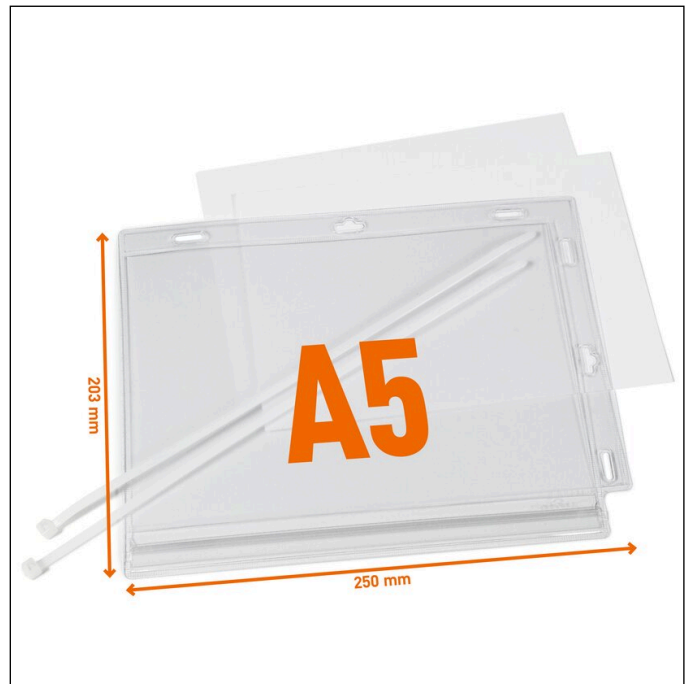

Product description

- Document pockets that are ideal for displaying information outside or in humid interior spaces such as garden centres, saunas or swimming pools where signs maybe be subjected to splashes and spray
- Waterproof press stud closure for very good document protection particularly in rain, highly humid spaces and areas that are wet and dirty
- The display pocket can be attached by using the 2 enclosed cable ties provided for this purpose in the long or Euro holes
- Compliant with standard IPX5 (protection against spray from all directions)
- Transparent, UV-stabilised, water-resistant, scratch-proof film with anti-glare effect
- For portrait and landscape formats
- Documents can be replaced quickly and easily
- Holds two 160 g/qm posters (included)
- A wide range of labelling style sheets is available at www.duraprint.de
- Suitable printable insert labels: Article number 485502
- Suitable also for US half letter-size formats

Product features

Outer width (mm)	203
Outer height (mm)	250
Outer depth / length	0.6 mm
Filling quantity / Filling quantity for	2 Sheet (80 g/sqm)
Format / Format for	A5
Orientation Format	Portrait / landscape

Water-resistant pocket A5 with cable ties

Brand	DURABLE
Inner width (mm)	155
Inner height (mm)	225
Opening	Long side
Protection flap	No
Thumb cut-out	No
Can be cut to size	No
With blank inserts	No
Colour Back Cover	Transparent
Product features relating to documents	Can be scanned, anti-glare
Attachment type	Cable ties
Label type	DURAPRINT®