




624-160-1
Diagonal Cutting Pliers 160 mm
Bimaterial Handles

PRODUCT DETAILS

- Side cutting pliers
- With induction hardened cutting edge for soft and hard wire
- Handles: soft grip bimaterial handles for comfort and control
- Finish: polished
- Material: High performance steel
- Max. cutting edge hardness: 60-65 HRC
- Standard: ISO 5749
- Max. cutting capacity: 1- copper wire, 2- medium hard wire

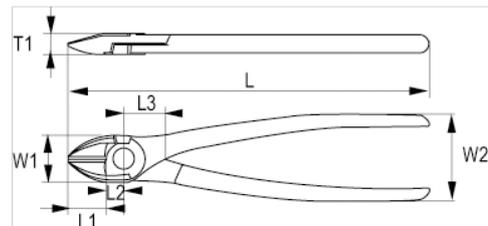

PRODUCT ATTRIBUTES

Product	L	L1	L2	L3	W1	W2	T1			
624-160-1	160 mm	21.5 mm	7 mm	13 mm	21.6 mm	50 mm	11.5 mm	1.6 mm	0.5 mm	200 g