

Rittal – The System.

Faster – better – everywhere.

► Component shelf for frame attachment Enclosure width 600 and 800 mm – DK 7486.035

Date : Apr 26, 2021

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Component shelf for frame attachment Enclosure width 600 and 800 mm – DK 7486.035

created: 26.04.2021 build on www.rittal.com/uk-en

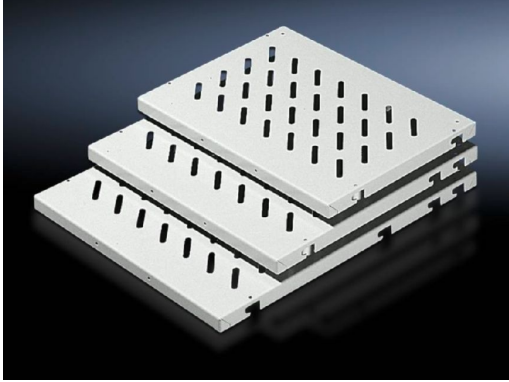

Product description

Design:	Slotted
Description:	For frame attachment, for installation in enclosures without 482.6 mm (19") accommodation.
Benefits:	Mounting bolts or mounting rails may be installed on a 25 mm pitch pattern in the enclosure depth. Mounting hole for handles provided.
Applications:	For installation in enclosures without 482.6 mm (19") accommodation
Material:	Sheet steel
Surface finish:	Spray-finished
Colour:	RAL 7035
Assembly instruction:	Additionally, two punched sections with mounting flanges are required for the inner mounting level
Supply includes:	Component shelf, slotted 2 mounting rails
Note:	Max. depth of component shelves = Enclosure depth - 100 mm.

Product description

To fit: Enclosure type: VX
Enclosure type: TS
Width: 800 mm

Dimensions: Width: 671 mm
Height: 45 mm
Depth: 600 mm

Installation options: Static installation: Component shelf, 50 kg with fixing bolts on punched section without mounting flange
Static installation: Component shelf, 100 kg with mounting rails on punched sections without mounting flange
Depth variable: Component shelf, 50 kg with telescopic slides on punched sections without mounting flange

Load capacity: 100 kg area load

Packs of: 1 pc(s).

Weight/pack: 9.93 kg

Copper weight (kg per piece): 0

EAN: 4028177166035

Customs tariff number: 94039010

ETIM 7.0: EC002620

ETIM 6.0: EC002620

eCl@ss 8.0/8.1: 27189261

eCl@ss 6.0/6.1: 27189261

Product description: DK Component shelf, WHD: 671x45x600 mm, 100 kg, For frame attachment, For W: 800 mm, RAL 7035

Approvals

Certificates: NA