


Geberit Mapress Stainless Steel corner elbow 90°



Example image

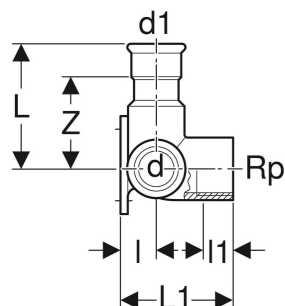

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ °C}$
- For saturated steam $\leq 120\text{ °C}$
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5

- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Two fastening points
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material

CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	l cm	l1 cm	Z cm
33503	12 / 15 / 12	15	1/2	15	90	6	4.3	1.3	1.5	4
33504	15 / 15 / 15	18	1/2	18	90	6	4.3	1.3	1.5	4
33505	20 / 15 / 20	22	1/2	22	90	6	4.3	1.3	1.5	4

Art. no.	DN	d, ø mm	Rp "	d1, ø mm	arc °	L cm	L1 cm	I cm	I1 cm	Z cm
33510	15 / 15 / 15	18	1/2	18	90	6	6.2	1.3	1.5	4
33520	20 / 15 / 20	22	1/2	22	90	6	6.2	1.3	1.5	4