



Datasheet EES80 Series


80W External Power Supply

ENGLISH



Features:

- 80W external power supply
- Protections: Short circuit/ Overload/ Over voltage
- Input voltage range: 100 to 240VAC
- Fully enclosed plastic case
- Efficiency: Up to 86%
- ErP step2 compliant (level V)

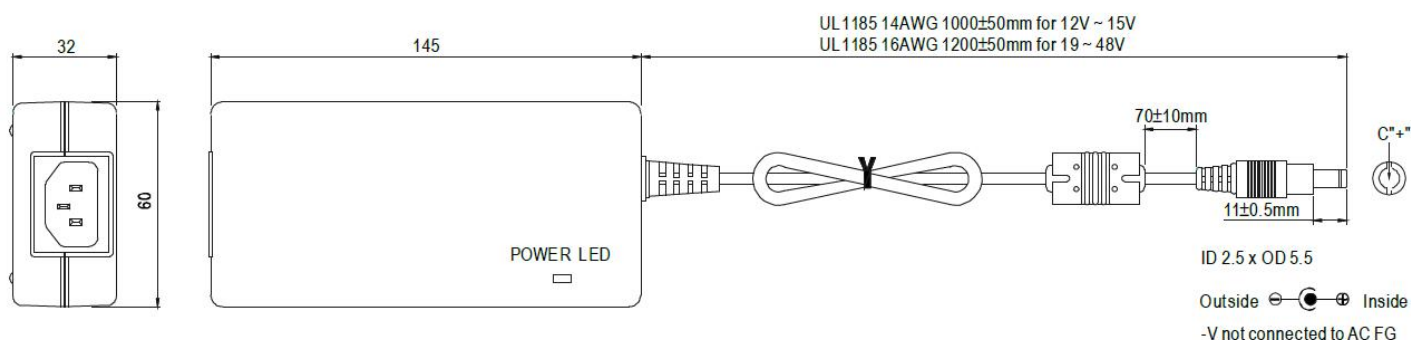

Model		784-0574	784-0577	784-0571	784-0580	784-0583
Output	DC Voltage	12V	15V	18V	24V	48V
	Rated current	6.67A	5.33A	4.44A	3.33A	1.66A
	Current range	0-6.67A	0-5.33A	0-4.44A	0-3.33A	0-1.66A
	Rated Power	80W				
Input	Voltage range	100-240VAC				
	Frequency range	47-63Hz				
	Efficiency	86%				
Protections	Short circuit	Auto recovery				
Environment	Working temperature	0°C - 40°C				
Other	Weight	540.4g				
	Dimensions	145*60*32mm (L*W*H)				
Connector	Plug	2.5mm				