



Oil



Heavy Duty

Heavy-duty nitrile-coated gloves with a jersey liner, for robust all-round hand protection

- **Heightened durability:** Stronger and more flexible than PVC, with three times greater durability than heavy-duty leather alternatives, ActivArmr® Hycron® 27-805 nitrile-coated work gloves meet ANSI/ISEA 105-2024 and EN ABRASION LEVEL 4 standards and are particularly suited to oily and greasy conditions
- **Optimized comfort:** Designed with wearer comfort in mind, ActivArmr® Hycron® 27-805 heavy-duty gloves possess a cotton jersey liner, which enhances their breathability, flexibility and overall user-friendliness
- **Reduced surface defect risks:** ActivArmr® Hycron® 27-805 abrasion-resistant gloves are also silicone-free, making them excellent for applications involving metals or automotive manufacture



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication
- Chemical

Applications


- Handling metal sheets & panels
- Metalworking & assembly operations
- Press injection molding
- Seizing and finishing structural parts
- Fixing, clipping parts and wire harnesses; connecting devices
- Assembly & inspection of components
- Opening furnaces draining pumps valves or lines and crackers BTX process

Key Features

- **Unique nitrile formulation:** Tough, hardy abrasion resistance*
- **Cotton jersey liner:** For protective gloves that ensure optimal comfort
- **Silicone-free design:** Suitably clean for metal and motor manufacture

*3x greater durability than standard leather alternatives

Performance Standards & Regulatory Compliance

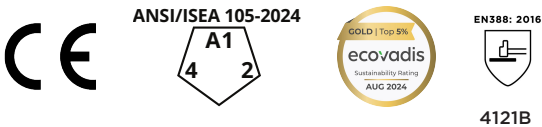

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COATING COLOR	PACKAGE
ActivArm® Hycron® 27-805	Finishing: Fully Coated Coating Material: Nitrile Liner Material: Cotton Jersey Cuff Style: Safety Cuff		9, 10, 11	256-272 mm/ 10.08-10.71 inches	Blue	12 pairs/bag, 12 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 900
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699