


## ENCLOSED HOSE REELS FOR COMPRESSED AIR / STEEL

DMF Series - Industrial type - Polyurethane hose



| Part number | Length (m) | Flow rate (l/min) | Temperature min/<br>max (°C) | Max. operating<br>pressure (bar) | Net weight (Kg) | Female thread | Profile   |
|-------------|------------|-------------------|------------------------------|----------------------------------|-----------------|---------------|-----------|
| DMF 0812IS  | 12.00      | 500.00            | -15.00 / 40.00               | 12.00                            | 6,4             | G3/8          | ISO 6150B |
| DMF 0812ES  | 12.00      | 500.00            | -15.00 / 40.00               | 12.00                            | 6,4             | G3/8          | EUROPEAN  |
| DMF 0812BS  | 12.00      | 500.00            | -15.00 / 40.00               | 12.00                            | 6,4             | G3/8          | BRITISH   |
| DMF 0812CS  | 12.00      | 500.00            | -15.00 / 40.00               | 12.00                            | 6,37            | G3/8          | ISO 6150C |

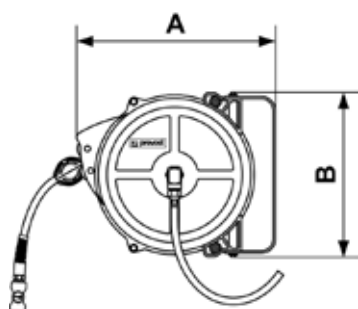

| Part number | Dim. A (mm) | Dim. B (mm) | Ø int/ext (mm) |
|-------------|-------------|-------------|----------------|
| DMF 0812IS  | 350.00      | 287.00      | 8.00 / 12.00   |
| DMF 0812ES  | 350.00      | 287.00      | 8.00 / 12.00   |
| DMF 0812BS  | 350.00      | 287.00      | 8.00 / 12.00   |
| DMF 0812CS  | 350.00      | 287.00      | 8.00 / 12.00   |