


Data Specification Sheet

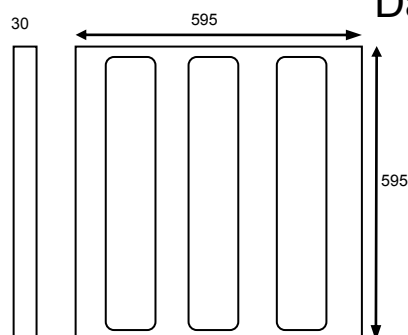

Recessed 600x600 36W LED Panel

Code	851-2914
Description	Recessed 36W LED modular Panel
Overall dimensions (mm)	(D)30mm (L)595mm (W)595mm
Product weight	3.5kg (c/w Driver)
Wattage	36W
Circuit Watts	36W
Lumen Output & Efficiency	3300Lm – 91Lm/W
Recommended product location	Indoor
Finishes available	White – Opal Diffuser
Output Colour	4200K Cool White
Control Gear Type	Remote Constant Current 1A 28V-46V Driver (Supplied)
Dimmable	No
Lamp Supplied	Yes – Non replaceable
Class	Class III.(LED Panel) Class II (Driver)
IP	IP20
Photometric Testing	Yes
Instruction sheet	Yes
Origin of manufacture	China
Main materials:	
• Chassis	Powder coated pressed steel
• Diffuser	3 x Opal Polycarbonate
Method of fix	Lay-in suitable for 600mm x 600mm recessed exposed 15mm & 25mm T ceilings.
Lampholder cap and make	Non replaceable 3 x 12w LED strips 2835 SMD LED
Electrical Connections	Direct plugin to remote driver
F mark	Yes
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of Conformity (Held on File)	Yes
Manufactured in accordance	EN60 598
Warranty	2 Years – 30,000 hour