

- Suitable replacement for 120W halogen or incandescent PAR38 lamp
- Up to 85% energy saving
- Dimmable
- Lifetime of 35,000 hrs
- Ideal for high efficient spot lighting in wide space areas like shops, corridors, conference centers



Order Code 52034

General Data

Lamp Socket E27
Design Lens

Geometric Data

Length (mm) 128.5
Diameter (mm) 119.5
Weight (g) 390

Electric Data


Wattage (W) 20
Voltage (V) 220 – 240
Power Factor ≥ 0.90
Operating Frequency (Hz) 50-60

Photometric Data

Luminous Flux (lm) 1200
CRI ≥ 80
CCT (K) 3000 K – warm white
Luminous Intensity (cd) 6500
Beam Angle (°) 22°
Lifetime (hours) 35,000 hrs

Switching Cycle 18,000

Equivalent to (W) 120

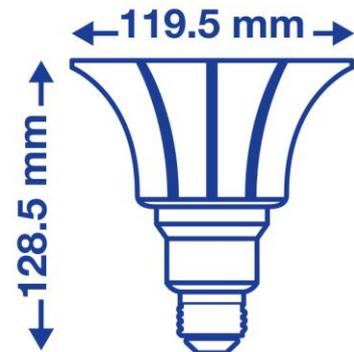



Order Code	52034
Product Description	LED PAR38 E27 20W 3000K WW 1200LM DIM

Technical Packaging Details

Barcode	023942520344
EAN 128	(02)00023942520344(37)04(91)162
EAN 14	50023942520349
Pack Dimensions (HxWxL)	140 mm x 128 mm x 128 mm
Pack Weight	480 g
Carton Qty (Shipping Unit)	4
Carton Dimensions (HxWxL)	180 mm x 280 mm x 280 mm
Cartons/Pallet	40
Layers/Pallet	5
Units/Pallet	160

Photometric Diagram

52034

