



SIVACON, door, right, ventilated, IP40, H: 2000 mm, W: 300 mm, RAL 7035, protection class 1

Model			
product brand name		SIVACON	
product designation		Door	
design of the product		With ventilation openings	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
operating resource protection class		safety class 1	
Appearance			
RAL color number		7035	
color		light grey	
Product details			
product component			
• ventilation		Yes	
• viewing door		No	
• door for disconnecter lock		No	
Mechanical Design			
height		2 000 mm	
width		300 mm	
opening direction of the door		right	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other
		 EG-Konf.	
		Special Test Certificate	Confirmation
			Miscellaneous
other	Environment		
Miscellaneous		Environmental Confirmations	
Further information			
Information on the packaging			
https://support.industry.siemens.com/cs/ww/en/view/109813875			

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1030-2UT14-2BA2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1030-2UT14-2BA2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1030-2UT14-2BA2

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

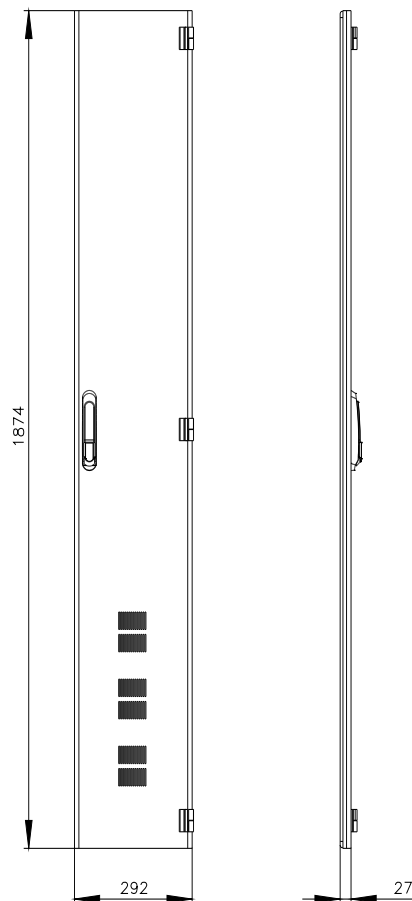

last modified:

4/13/2025 

