


## Features

- Cleanroom Technical Paper
- A4 / 75gsm
- ISO 6 cleanroom processed
- Ultra-low ionic contamination, particle and fibre generation
- RoHS compliant

## RS PRO Cleanroom Office Supplies

RS Stock No.: 0218666

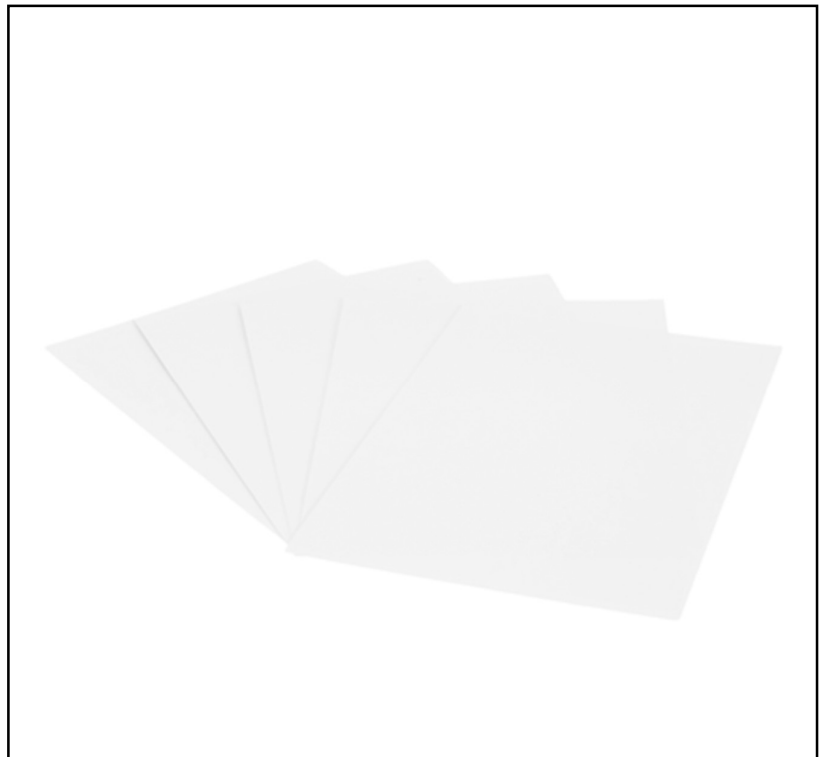

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

## Product Description

*The Cleanroom Technical Paper is ISO 6 Cleanroom processed and features excellent resistance to IPA. It is compatible with most inks, ensuring smudge-free writing.*

*The paper boasts ultra-low ionic contamination and generates minimal particles and fibers. It is highly heat resistant, making it suitable for use in laser printing and photocopiers.*

*ROHS compliant with a weight of 73 g/m<sup>2</sup>, its dimensions are 8.3 " x 11.7 " (210mm x 297mm).*

*Ideal for note-taking, printing, and creating forms or log sheets.*

## General Specifications

Product Type	Cleanroom Technical Paper
Weight	75gsm
Colour	White
Size	A4 (210mm x 297mm)
Smoothness:	
Front side	42 ↑ (Standard 40 ± 10)
Reverse side	38 ↑ (Standard 40 ± 10)
Wet Tensile Strength:	
MD	1.16 kg/15mm
CD	1 kg/15mm
Dry Tensile Strength:	
MD	7.90 kg/15mm
CD	5.30 kg/15mm

## Particle Data

Particle (Dry)		
≥0.3µm	221 count/ft <sup>3</sup>	Testing method: IES-RP-CC003.3
≥0.5µm	139 count/ft <sup>3</sup>	
≥1.0µm	82.4 count/ft <sup>3</sup>	

## Approvals

Complies with EN 61340-5-1	Yes
----------------------------	-----

## Similar Products

Stock No.	Brand	Product Name	Colour	Size	Quantity
0218666	RS PRO	Cleanroom Technical Paper	White	A4	Per pack - 250 sheets