


# DX06LR012B Datasheet

Product Name // DX06LR012B, 6mm Diameter, Solder Lug, Red, 12V, Black Plated Brass

 [View Product Page](#)

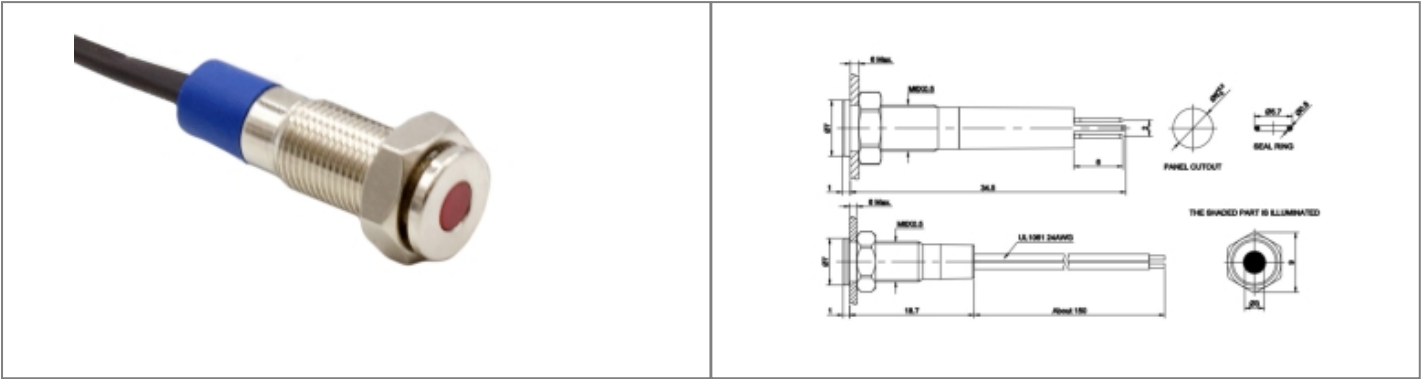

// Product Description:

- |                                                                                                 |                                                                                                        |
|-------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------|
|  DX Series     |  Red                  |
|  6mm Diameter |  12V                 |
|  solder Lug  |  Black Plated Brass |

// General Information:

|                                  |                                         |
|----------------------------------|-----------------------------------------|
| Product Display Title:           | 6mm Vandal Resistant Indicator DX Range |
| Product Family:                  | Indicators                              |
| Product Series:                  | 6mm Vandal Resistant Indicator DX Range |
| Bezel Finish:                    | Gloss                                   |
| Body Colour:                     | Black                                   |
| Body Material:                   | Brass                                   |
| Body Material Type:              | Metal                                   |
| Diameter:                        | 6mm                                     |
| Dielectric Withstanding Voltage: | 1500V                                   |
| Function:                        | Vandal Resistant Indicator              |
| Illumination Colour:             | Red                                     |
| Illumination Voltage:            | 12V                                     |
| Indicator Profile:               | Flat-round                              |
| Insulation Resistance:           | ≥100MΩ(500VDC)                          |
| Ip Rating:                       | IP67                                    |
| Material Finish:                 | Gloss                                   |
| Max Operating Temperature:       | 55°C                                    |
| Min Operating Temperature:       | -25°C                                   |
| Max Panel Thickness:             | 6mm                                     |
| Panel Cut Out:                   | 6mm Diameter circle                     |
| Rohs Compliant:                  | Yes                                     |
| Thread Size:                     | M6 X 0.5                                |

// Product PDF Links

 [6mm & 8mm Vandal Resistant...](#)

// Product 3D CAD Model Links

 [DX06LR012B3D CAD Model](#)



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)