

## Product Datasheet


**SCSI Ultra 320 HPDB68 M/M**

Cable, latch type


**RS Stock No. 8011171****RS Stock No. 8011178****RS Stock No. 8011174****ELECTRICAL SPECIFICATIONS**

1. Rating: Temp 80°C Voltage 30V
2. Conductor Resistance: AT 20°C MAX.  
30AWG:376.96.Ω/KM
3. Impedance Resistance: 10M Ω/km min  
at 20°C dc 500V
4. Dielectric Strength: AC 500V/1 minute.

**SPECIFICATION**

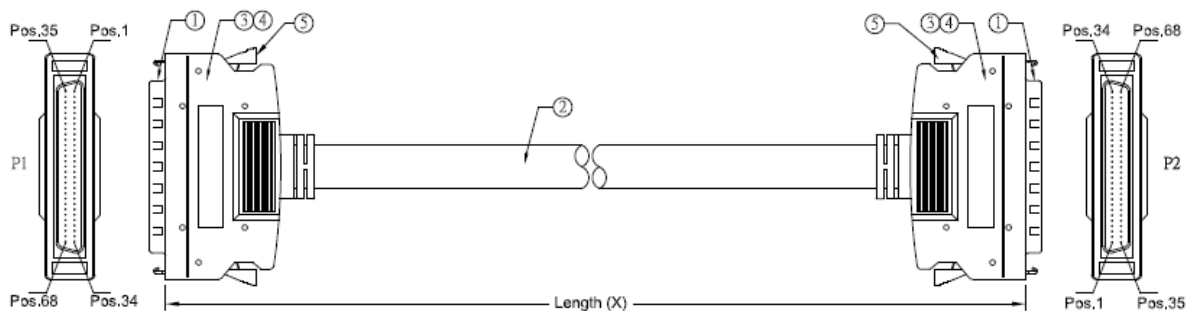

PIN ASSIGNMENT:

 

Prat No	Length(X)
8011171	1000±30
8011178	2000±50
8011174	3000±50

5	4	EA	Latch A4 Type, Color : Black
4		MM	Copper Foil 360° Soldered
3		KG	Molded 40P PVC Color:Black(BK01).
2	1	EA	UL2919 30AWG 34TW/PR,Al/Mylar+Drain +Braid, Color:Black(BK01).
1	2	EA	HPDB68 Male, Pitch1.27mm, Shell: Tin Plated Contact:Gold 10U*,Insulation:Black,PBT UL94V-0
ITEM	QTY	U/M	DESCRIPTION

Package:

1pcs/PE bag

