


## Technical data

KH1630

Ball sleeves



### VISUAL (S)

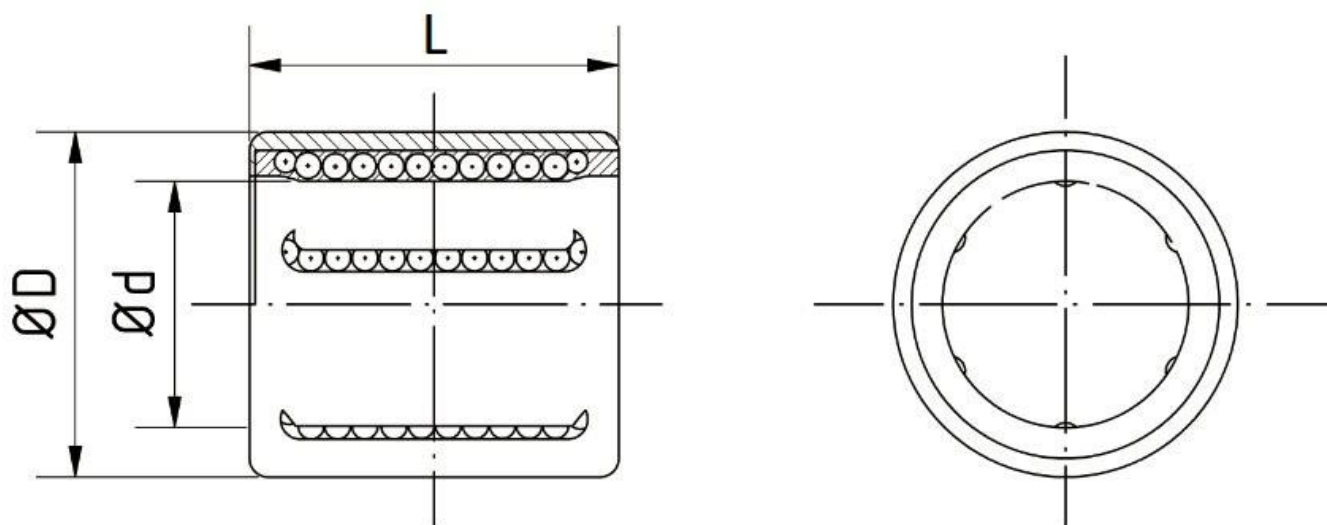

### PRODUCT DEFINITION

|                                           |                       |
|-------------------------------------------|-----------------------|
| Brand                                     | NTN                   |
| Design type                               | KH                    |
| Ball bushings category                    | Ball sleeves          |
| Standard                                  | ISO dimension         |
| Material outer cylinder or steel segments | hardened steel sleeve |
| Material Cage                             | PA                    |
| Initial greasing                          | Non/No                |
| Re-lubricable                             | Oui/Yes               |
| d - Internal diameter                     | 16 mm                 |



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                              |          |
|------------------------------|----------|
| <b>D - External diameter</b> | 24 mm    |
| <b>L - Length</b>            | 30 mm    |
| <b>Number of ball rows</b>   | 5        |
| <b>Mass</b>                  | 0,027 kg |

## PRODUCT PERFORMANCE

|                                         |           |
|-----------------------------------------|-----------|
| <b>Cmin</b>                             | 775000 mN |
| <b>Cmax</b>                             | 775000 mN |
| <b>C0min</b>                            | 600000 mN |
| <b>C0max</b>                            | 600000 mN |
| <b>Tmin - Min operating temperature</b> | 253,15 °K |
| <b>Tmax - Max operating temperature</b> | 353,15 °K |

