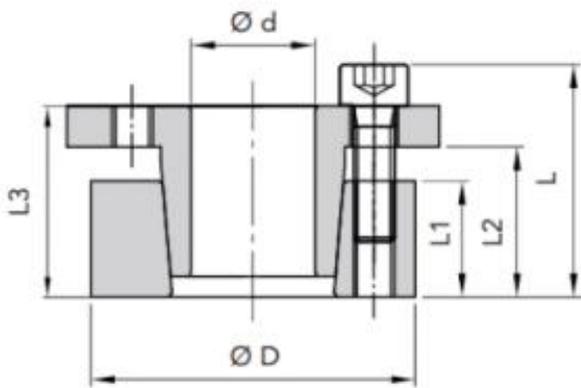


06160060

RCK 16 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06160060
Ød (DD) mm	60
ØD (D) mm	90
L1 (L1) mm	20
L2 (L2) mm	25
L3 (L3) mm	33
L (L) mm	41
Maximum torque Mt (MT) Nm	2500
Clamping pressure - Shaft (CPS) N/mm ²	185
Clamping pressure - Hub (CPH) N/mm ²	125
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	8
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x25
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Extraction thread - Type (ETT)	M8
Extraction thread - Num. (ETN)	4
Weight (WEIGHT) kg	0.90