




## Datasheet

ENGLISH





### 8 way PCB terminal block 5.08mm

RS Stock 790-1082

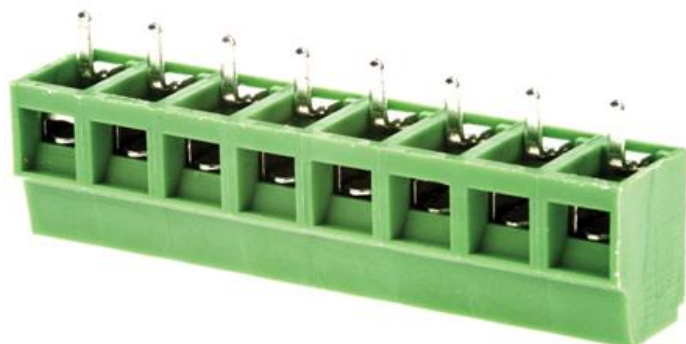

#### Dimensions: (mm)

##### PCB Layout

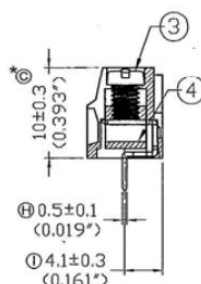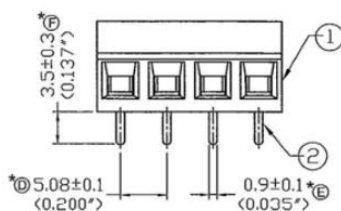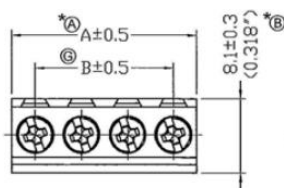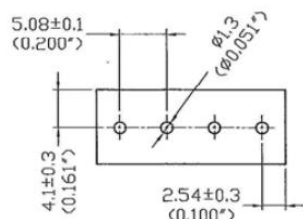

#### Specification

Current Rating: 16Amp AC300V  
 Insulation Withstands Volts: AC2000V Min  
 Insulation Resistance: >2000M  $\Omega$  DC500V  
 Operation Temperature: -40°C to + 105°C  
 Wire Strip Length: 4mm~5mm  
 Wire Range: 14~26AWG  
 Screw Torque: 4.5lb-inch

#### Material

Insulating Body: Polyamide 66(UL94V-0)  
 Slide Cover: Polyamide 66(UL94V-0)  
 Contact Pin: Phosphor Bronze / Finish: Tin Plated  
 Colour: Green