




LED Special Ba15d T17X56 3W (37W) 420lm 830

Article number: 141869

BAI LED Compact Tube 17x56mm Ba15d 3W 3000K 420lm (37W) Clear 230V-240V 300° LED-lamp

The LED compact series consists of lamps that are ideal as replacements for conventional lamps due to their compact design and high luminous flux. Ambient temperature range: -20°C to +40°C.

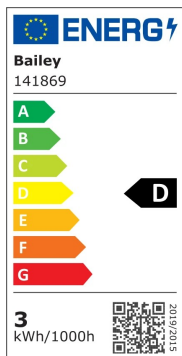

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Special Ba15d T17X56 3W (37W) 420lm 830
Brand	Bailey
Productseries	LED Special
Producttype	T17X56 BA15D 830 CL

ETIM specifications

Socket	BA15d
Luminous flux [lm]	420 - 420
Nominal voltage [V]	220 - 240
Lamp power [W]	3 - 3
Colour temperature [K]	3000 - 3000
Diameter [mm]	17
Length [mm]	56
Dimmable	No
Lamp shape	Tube, single-ended
Beam angle [°]	300 - 300
Colour	White
Type of glass/cover	Clear
Lamp designation	Other
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Rated luminous flux according to IEC 62612 [lm]	110
Power factor	0.9
Lamp efficacy [lm/W]	140
Nominal current [mA]	35 - 35
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM5
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	3
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	Other
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	D
With twilight switch	No
Material of light bulb	Plastic

Alternative articles



142195

LED FIL T20X60 Ba15d DIM
2.5W (18W) 170lm 827 Clear