

PRODUCT DATASHEET

WORK VAL 3POD 2x30 W 4000 K IP65

WORKLIGHT VALUE 3POD | Versatile LED worklight with tripod stand



AREAS OF APPLICATION

- Renovation
- Garages
- Basement
- Workshops

PRODUCT BENEFITS

- Foldable for easy storage
- Energy savings of up to 80% compared to halogen lamp worklights
- Semi-frosted, tempered glass cover for uniform illumination
- 3 years guarantee

PRODUCT FEATURES

- "Plug and play" worklights with up to 9000 lm
- Rotation angle luminaire head: 360°, swiveling: 180°
- Die-cast aluminum housing with PC front cover
- Type of protection, luminaire head and housing: IP65, Type of protection, plug: IP44
- Height adjustment of tripod up to 1.8 m total height
- Quick-release fastener for adjustment of luminaire head angle
- Type E/F plug



TECHNICAL DATA

Electrical data

Nominal wattage	60.00 W
Operating mode	Integrated LED driver
Nominal voltage	220...240 V
Mains frequency	50/60 Hz
Power factor λ	> 0.90
Total harmonic distortion	< 20 %


Photometrical data

Color temperature	4000 K
Color rendering index Ra	≥ 80
Light color (designation)	Cool White
Luminous flux	5400 lm
Luminous efficacy	90 lm/W
Standard deviation of color matching	≤ 6 sdc _m

Light technical data

Beam angle	110 °
------------	-------

— Dimensions & weight

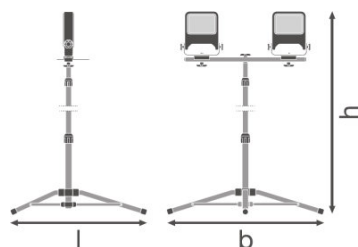

Length	680.0 mm
Width	780.0 mm
Height	1750 mm
Product weight	3920.00 g
Cable length	2000 mm

Colors & materials

Product color	Black
---------------	-------

Housing color	Black
Body material	Aluminum
Cover material	Glass

Temperatures & operating conditions

Ambient temperature range	-20...+45 °C
----------------------------------	--------------

Lifespan

Number of switching cycles	10000
Lifespan L70/B50 at 25 °C	30000 h

Additional product data

Mounting type	Standing
Mounting location	Floor

Capabilities

Dimmable	No
Type of connection	Protective contact Plug type
LED module replaceable	Not replaceable

Certificates & standards

Type of protection	IP65 ¹⁾
Protection class	I
Protection class IK (shock resistance)	IK06
Glow Wire Test according to IEC 60695-2-12	650 °C
Photobiological safety group EN62778	RG 1
Luminaire with limited surface temperature, class "D"	No
Standards	CE/CB/EAC/RoHS

¹⁾ Luminaire head and housing IP65, plug IP44





Detail

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075308855	Folding carton box 1	189 mm x 189 mm x 644 mm	4154.00 g	23.00 dm ³
4058075308862	Shipping carton box 4	395 mm x 395 mm x 665 mm	17597.00 g	103.76 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

ADDITIONAL CATALOG INFORMATION

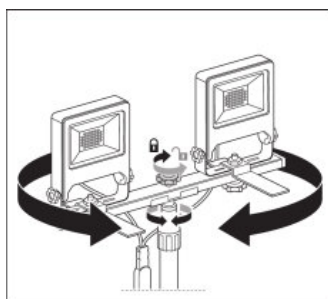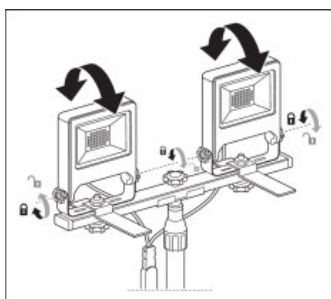

REFERENCES / LINKS

For Guarantee see
 ▶ www.ledvance.com/guarantee

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.