


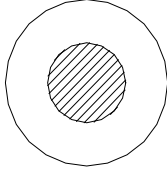

Product Name:	UL1429 20AWG
Product Discription:	UL1429 20AWG
Specification No.:	
Customer's Name:	

Description					
Rated Voltage:		150V			
Rated Temperature:		80℃			
Reference Standard:		UL758,UL1581			
Cross Section					
					
Marking					
E148000 Ⓡ AWM STYLE 1429 20AWG 80℃ 150V VW-1 --- C Ⓡ AWM I A 80℃ 150V FT1 -F- -LF- PC10 LTK					
Applications					
For Internal Wiring of Appliances or Electronic Equipment					
Revisions					
Version	Description	Drawn by	Approved by	Date	
0	New document issue	Lisa	Jason	18/05/2015	
Construction					
Conductor		Stranded Tinned Copper			
Size(AWG)		20			
Construction(±0.008mm)		26/0.16			
Stranded Dia.(mm)Ref.		0.94			
Insulation Material		XLPVC			
Insulation Color		ANY COLOR			
Ave Thickness(mm)		0.26			
Insulation Dia.(±0.06mm)		1.46			
Remark:					
8775392 Red		8775395 Blue	8775415 Grey	8775418 Violet	
8775389 Black		8775399 White	8775402 Yellow		
8775383 Brown		8775409 Green	8775406 Orange		
Characteristics					Customer Approve
Test Item			Standard Value		Seal & Stamp
Test Material			XLPVC(ROHS)		
Insulation DC resistance(MΩ*km)			10		
Vol. Tesr(AC.V.60S) (V)			2000		
Flammability Test			VW-1		
Max.DC Resistance(20℃ Ω/km)			34.6(MAX)		
					Signature: Date: