


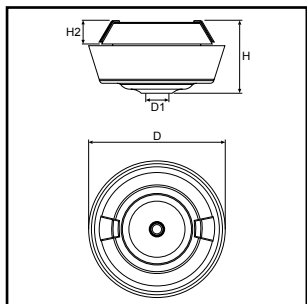

Material

TPE and Polyamide 66 - Halogen Free
UL approved material

Integrated cable anchorage,
wide sealing range.
Material thickness 1,5 - 5 mm
Material thickness IP67/65 2 - 5 mm
Quick and simple assembly without
the use of tools.

Mode of protection

IP67 / IP65


Temperature range

-20°C....+125°C ⁽¹⁾

Test standard

EN60529:1991+A1
EN50262:1998
EMKO-TUI (03-SEC) FI001/84
606620

Semko report

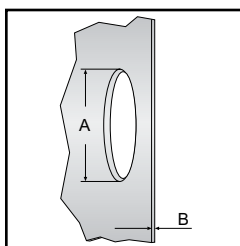

E-number	Size	IP67 and Cable Ancho- rage Type A* for Cable Ø mm	IP65 for Cable Ø mm	A mm	B for IP67/65 mm	H mm	H2 mm	D1 mm	D*** mm	Pcs pack	
----------	------	---	---------------------------	---------	------------------------	---------	----------	----------	------------	-------------	--

RAL 7035

T_14 758 03	M20	7 - 11	4 - 11	20,5	2 - 5	17 - 20	5,5	4,0	29,3 - 34,5	50	2500
T_14 758 04	M25	7 - 13**	4 - 13	25,5	2 - 5	17 - 20	5,7	5,0	34,3 - 40,0	50	2000

RAL 9005

T_14 758 13	M20	7 - 11	4 - 11	20,5	2 - 5	17 - 20	5,5	4,0	29,3 - 34,5	50	2500
T_14 758 14	M25	7 - 13**	4 - 13	25,5	2 - 5	17 - 20	5,7	5,0	34,3 - 40,0	50	2000

RAL 9010

T_14 758 23	M20	7 - 11	4 - 11	20,5	2 - 5	17 - 20	5,5	4,0	29,3 - 34,5	50	2500
T_14 758 24	M25	7 - 13**	4 - 13	25,5	2 - 5	17 - 20	5,7	5,0	34,3 - 40,0	50	2000

RAL XYZ

TKS M20 XYZ	M20	7 - 11	4 - 11	20,5	2 - 5	17 - 20	5,5	4,0	29,3 - 34,5	50	2500
TKS M25 XYZ	M25	7 - 13**	4 - 13	25,5	2 - 5	17 - 20	5,7	5,0	34,3 - 40,0	50	2000

* Cable Anchorage Type A, according to EN 50262.

** 8,1 - 8,9 mm only approved for tension relief.

*** Varies depending on the thickness of material installed in.

(1) Unstressed material.