


Shut-off valve HE-N1/2-LO

Part number: 197130

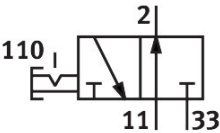

Data sheet

[General operating condition](#)

Feature	Value
Sealing principle	Soft
Exhaust-air function	Without flow control option
Type of piloting	Direct
Symbol	00991672
Operating pressure	1 bar ... 10 bar
C value	28.13 l/sbar
b value	0.28
Standard nominal flow rate (standardised to DIN 1343)	6200 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Type of mounting	Screw-in
Mounting position	optional
Flow direction	Non-reversible
Product weight	1100 g
Pneumatic connection, port 1	1/2 NPT
Pneumatic connection, port 2	1/2 NPT
Pneumatic connection, port 3	1 NPT
Material seals	NBR TPE-U(PU)
Material housing	Die-cast aluminium