

## High-comfort, chemical resistant, 0.425 mm glove for a wide range of applications

- High performance nitrile compound, providing an outstanding combination of chemical resistance and strength for optimal results in wet or dry work environments
- The glove offers a far superior snag, puncture and abrasion protection compared with rubber or neoprene gloves
- High levels of flexibility, comfort and dexterity
- Suitable for heavy-duty cleaning applications



### Industries

- Automotive
- Automotive Aftermarket
- Food Processing
- Metal fabrication
- Oil and gas
- Chemical

### Applications

- Delivery of parts to production line
- Welding
- All food processing applications that have food contact
- Forging operations
- General pumping work
- Handling incoming goods
- Filling, blending and charging of raw materials
- Opening and draining pumps valves or lines
- Loading and unloading of process equipment
- Transferring liquids and solids between vessels and tanks and process equipment
- Supervision of running operation
- Handling outgoing goods: cans, vessels, bulkpack and cartons
- Testing
- Opening furnaces draining pumps valves or lines and crackers BTX process
- Painting or cleaning tools or robots

Previously known as: Solvex® 37-695

### Key Features


- Cotton flocking, reducing sweat for the wearer
- Fully reusable, with an unequaled abrasion resistance
- Provides superb comfort for the wearer
- Reversed lozenge finish further enhancing levels of grip

### Vulcanization Chemical Accelerators

- Mercaptobenzothiazole
- Zinc Diethyldithiocarbamate

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

### Performance Standards

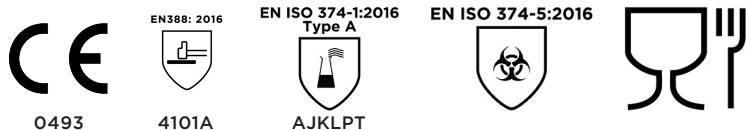

### Specifications

BRAND   STYLE	DESCRIPTION	SIZE	LENGTH	COLOR	PACKAGE
AlphaTec® Solvex® 37-695	Cotton Flocking, Nitrile,	7, 8, 9, 10, 11	380 / 15	Green	• 12 pairs/polybag, 6 polybags/carton

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### Canada

Ansell Canada Inc.  
105, rue Lauder  
Cowansville (Québec)  
J2K 2K8, Canada  
T: 1 800 363-8340  
F: 1 888 267-3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.