

## Features

- Metric thread
- IP68 rated against dust and excellent water resistance
- UL approved nylon claw, UL94-V2. NBR o-ring, NBR hermetic sealx

## RS PRO Light Grey Nylon Cable Gland With Strain Relief, M20 Thread, 6mm-11mm Cable Range, IP68

RS Stock No.: 0358128



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description


A high quality nylon cable gland with nitrile rubber o-ring, hermetic seal coil shaped strain relief. These cable glands offer excellent strain relief and cable protection. Cable glands allow you to safely and securely mount a cable through a hole. These are commonly used in enclosures, on various types of equipment and machinery and in the construction industry.

## General Specifications

Thread size	M20x1.5
Material	Nylon and NBR
Cable range	6-11mm
Colour	Light Grey (RAL 7035)
Application	Enclosures, HVAC, machinery, equipment, construction industry

## Mechanical Specifications

A	20
B	10
C	24
Thread size	M20x1.5
Cable range	6-11

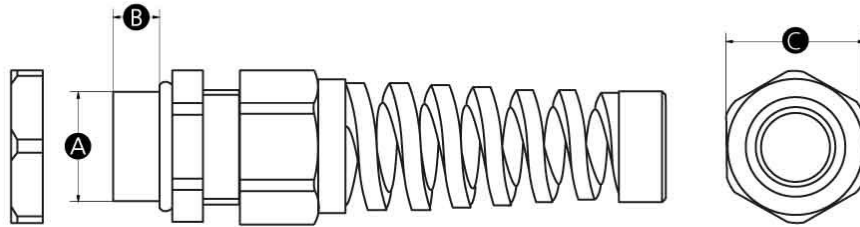

## Similar Products

Stock No.	Brand	Product Name	Thread size	Cable range
0358123	RS PRO	Black Nylon Cable Gland	M22x1.5	8-13mm
0358124	RS PRO	Black Nylon Cable Gland	M24x1.5	12-15mm
0358125	RS PRO	Light Grey Nylon Cable Gland	M22x1.5	8-13mm
0358127	RS PRO	Light Grey Nylon Cable Gland	M30x1.5	16-21mm