



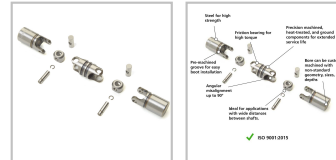

UD8-XX-XX-F-KIT

Ruland UD8-XX-XX-F-KIT, Machinable Bore Double Universal Joint Kit, Friction Bearing, Steel, 0.495" (12.6mm) OD, 2.813" (71.5mm) Length

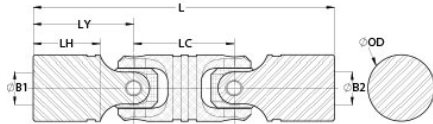

Description

Ruland UD8-XX-XX-F-KIT is a double cardan friction bearing universal joint kit that can be machined with a bore size and geometry of the user's choice. It has a 0.495" (12.6mm) OD and 2.813" (71.5mm) length. UD8-XX-XX-F-KIT is ideal for applications with wide distances between shafts and can accommodate all forms of misalignment. This plain bearing double universal joint is comprised of pins and blocks that are precision machined, selectively heat treated, and ground for high strength, accuracy, and wear resistance. The combination of these components with precision ground and hardened yoke ears allow for a longer lifespan, increased performance in demanding applications, and greater angular misalignment of up to 90° when compared to commodity style double universal joints. UD8-XX-XX-F-KIT is made from high grade alloy steel for durability and high strength. It can be combined with boot UBOOT8/13-NI-KIT to protect the joints from unwanted contaminants such as dust or water and self lubricate reducing maintenance time. This double cardan universal joint is manufactured in the USA by Belden Universal for strict control of processes.

Product Specifications

Bore (B1)	No Bore	Small Bore (B2)	No Bore
B1 Max Shaft Penetration	0.740 in (18.8 mm)	B2 Max Shaft Penetration	0.740 in (18.8 mm)
Joint Outer Diameter (OD)	0.495 in (12.6 mm)	Length (L)	2.813 in (71.5 mm)
Center Yoke Length (LC)	0.813 in (20.7 mm)	Yoke Length (LY)	1.000 in (25.4 mm)
Hub Depth (LH)	0.740 in (18.8 mm)	Max Round Bore (Inch)	0.2813 in
Max Round Bore (Metric)	7 mm	Max Hex or Square Bore (Inch)	0.2813 in
Max Hex or Square Bore (Metric)	7 mm	Max Blind Bore (Inch)	0.3750 in
Max Blind Bore (Metric)	9 mm	Peak Torque	315 in-lb (35.6 Nm)
Rated Torque	63 in-lb (7.1 Nm)	Max Operating Angle	90°
Material Specification	Alloy Steel	Manufacturer	Belden Universal
Country of Origin	USA	Weight (lbs)	0.125000
Recommended Lubricant	LUBRIPLATE No. 1200-2	Matching Boot Cover	UBOOT8/13-NI-KIT
UPC	634529289013	Tariff Code	8483.60.4000
UNSPC	25173810		
Note 1	Performance ratings are for guidance only. The user must determine suitability for a particular application.		
Prop 65	 WARNING This product can expose you to the chemical Ethylene Thiourea, known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov .		