



Datasheet

ENGLISH

5mm Pitch Standard Profile Terminal Block

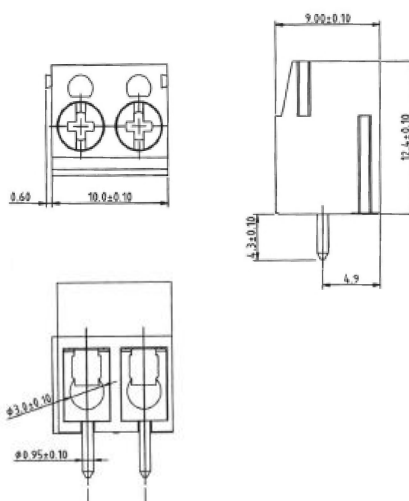

TYPE NO.	POLES	LENGTH
8966696	2	10mm
8970705	3	15mm
8970708	4	20mm
8970702	5	25mm
8970711	6	30mm
8970714	7	35mm
8970718	8	40mm
8970727	9	45mm
8970720	10	50mm
8970724	11	55mm
8970733	12	60mm

- 2-12 pole interlocking
- Moulded in black
UL94V-0 PA Flame retardant PA66
- Wire protector terminals
- 0.3-2mm² (22-14 AWG)
- Guided pin alignment
-  us approved

SPECIFICATION

Rating	16A 250V
Insulation resistance	5000MΩ/1000V
Withstand Voltage	AC1500V/1min
Contact Resistance	20mΩ
Working Temperature	-33°C to +120°C
Mouldings	UL94-V0 flame retardant PA66
Wire Protector	Stainless steel
Screw/Torque	M3 Steel, Nickel Plated 0.4Nm
Recommended PCB hole size	ø1.2mm-1.4mm