


34071 -- 1 of 1 products

Terminals and Splices
Splices - Closed Barrel

- General** **INFO**
- Sales** **INFO**
- Customer Drawings** **SPECIFICATIONS**

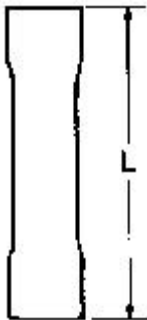

Line art represents typical product only.

<i>Searchable Features:</i>	
Product Type	Splice
Splice Type	Butt
Butt Splice Type	Standard
Body Style	PLASTI-GRIP
Insulation	Yes
Insulation Support	Insulation Support
Insulation Diameter	.170 [4.32] Max. in. [mm]
Wire Range	16-14 [1.04-2.62 ²] AWG [mm]
Wire Range (CMA)	2,050-5,180
Material	Copper
Finish	Tin
Packaging Method	Loose Piece
<i>Other Properties:</i>	
Dim. L	1.065 [27.05] Max. in. [mm]
Insulation Sleeve Material	Vinyl
Color	Blue
CERTI-CRIMP Hand Tool	47387-7, 525691-0 (Great Britain Tool)
CERTI-LOK Hand Tool Frame Assembly	169400
CERTI-LOK Die Assembly	169404

[[Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#)]
[Top of Page](#)