 




Product Features

- Power required from one end only
- Uniform light output across the entire length of 15 metres
- Colour Changing RGB + Single Colour White
- Industrial grade adhesive backing tape
- Operating temperature -20°C ~ +40°C
- High efficacy
- 3 years warranty



Specifications

Stock Code	4797-951 	5142-960 	5303-944 	4380-914 
Part Code	RGB27K-48-100-20	RGB30K-48-100-20	RGB40K-48-100-20	RGB60K-48-100-20
Voltage	48VDC	48VDC	48VDC	48VDC
Power Consumption	19.2W/m	19.2W/m	19.2W/m	19.2W/m
Total Lumen Output	850lm/m	850lm/m	850lm/m	850lm/m
Colour Temperature	RGB + 2700K	RGB + 3000K	RGB + 4000K	RGB + 6000K
LED/metre	100+100	100+100	100+100	100+100
Beam Angle	120°	120°	120°	120°
Cut Points	100mm	100mm	100mm	100mm
CRI (Ra)	>80	>80	>80	>80
IP Rating	IP20	IP20	IP20	IP20
Dimensions	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm	15000 x 12 x 1.8mm



RGB

2700K

3000K

4000K

6000K





Product Features

- Power required from one end only
- Uniform light output across the entire length of 15 metres
- Colour Changing RGB + Single Colour White
- Industrial grade adhesive backing tape
- Operating temperature -20°C ~ +40°C
- High efficacy
- 3 years warranty



Specifications

Stock Code	5150-920	4841-925	4467-952
Part Code	RGB30K-48-100-65	RGB40K-48-100-65	RGB60K-48-100-65
Voltage	48VDC	48VDC	48VDC
Power Consumption	19.2W/m	19.2W/m	19.2W/m
Total Lumen Output	765lm/m	765lm/m	765lm/m
Colour Temperature	RGB + 3000K	RGB + 4000K	RGB + 6000K
LED/metre	100+100	100+100	100+100
Beam Angle	120°	120°	120°
Cut Points	100mm	100mm	100mm
CRI (Ra)	>80	>80	>80
IP Rating	IP65	IP65	IP65
Dimensions	15000 x 12 x 3mm	15000 x 12 x 3mm	15000 x 12 x 3mm



RGB+W

15 metres of uniform light output, powered from one end



Compatibility*



Control Methods (sold separately)

- Remote Control
- Bluetooth (Apps, Voice Control)
- Sound Reactive (colour changing, dimming)
- Hard-wired wall-mounted controller
- RF wall-mounted or remote controlled

Suggested Drivers

Up to 7m

Power supplied from ONE end

HLG-150H-48A

Up to 15m

Power supplied from ONE end

HLG-320H-48A


Up to 30m

Power supplied from MIDDLE


HLG-600H-48A

Mechanical Diagram

IP20

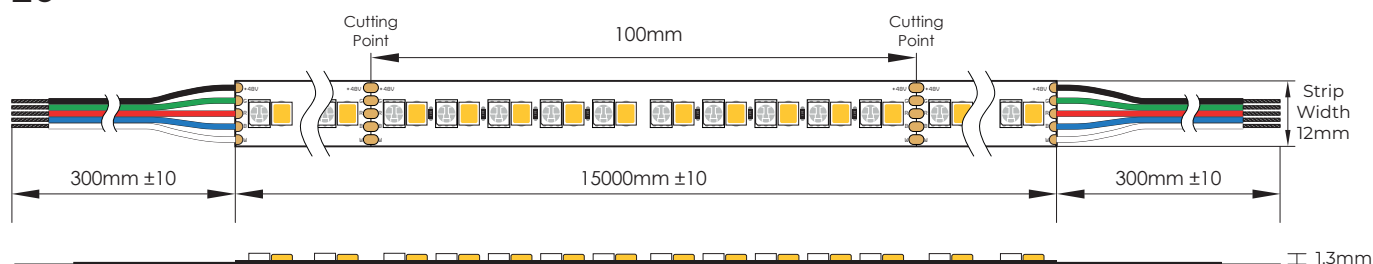


IP65

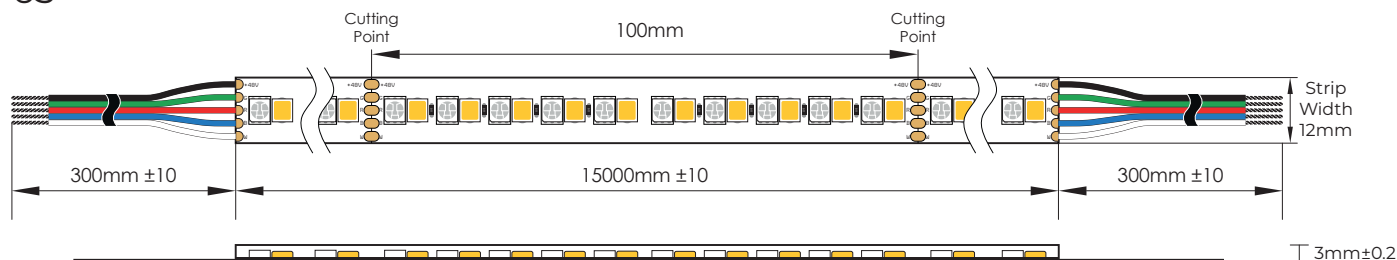


* Product compatibility with other brands is shown for informational purposes only. All third-party company names and logos are trademarks of their respective owners and do not constitute an endorsement or partnership with our company.

Connectors (sold separately)

WIRE TO WIRE

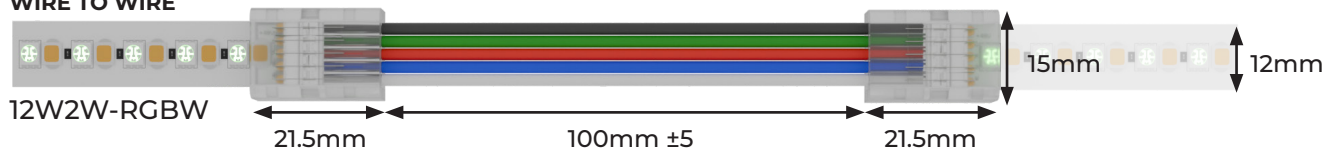

TAPE TO DRIVER

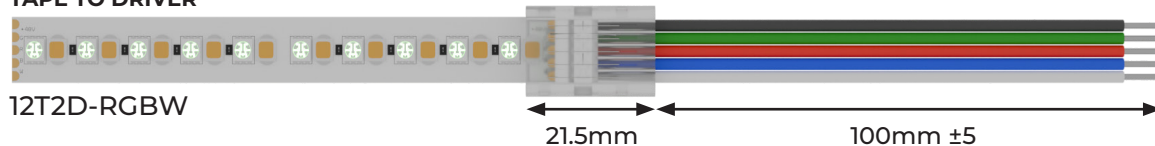

TAPE TO TAPE

