

Features

- Maximum operating pressure is 35 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel Nickel-Plated Finish
- Single Shut Off (One side is with valve)
- Euro Profile
- DN7.8
- Flow 1800 l/min
- Compatible with:
TST SWING COUPLING C
TST 026
PARKER - RECTUS 25, 26
CEJN 320
JWL 520, 530
PARKER PEF
LEGRIS

RS PRO Pneumatic Quick Connect Coupling

RS Stock No.: 0325468



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

RS PRO Series 25 Quick Connect Couplings


Pneumatic quick-connect coupling connectors are found across industry in pneumatic systems as diverse as robotic assembly lines and other equipment.

- Maximum operating pressure is 35 bar.
- Operating temperature range -20°C to +100°C.
- Material: Brass / Steel Nickel-Plated Finish
- Single Shut Off (One side is with valve)
- Euro Profile
- DN7.8
- Flow 1800 l/min
- Compatible with:
TST SWING COUPLING C
TST 026
PARKER - RECTUS 25, 26
CEJN 320
JWL 520, 530
PARKER PEF
LEGRIS


Specifications

Manufacturer Series	025
Coupling Type	Quick Connect Coupling Socket
Connection Standard	DN 7.8 Euro Profile
Connection Standard Compatible With	TST SWING COUPLING C; TST 026 ; PARKER - RECTUS 25, 26; CEJN 320; JWL 520, 530; PARKER PEF; LEGRIS
Minimum Operating Temperature	-20°C
Maximum Operating Temperature	+100°C
Maximum Operating Pressure	35bar
Flow	1800 l/min
Flow Direction & Sealing	Self-sealing coupling
Material	Brass, Steel
Finish	Nickel Plated
Connection Type	Threaded
Thread Size	1/2 in
Thread Standard	R
Thread Gender	Male
Coupling Gender	Female
Threaded Connection	R 1/2 Male
Seal material	Nitrile Rubber
Hose Barb Connection	N/A



Specifications

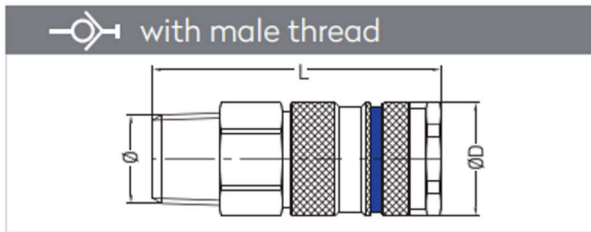

Dimensions (mm)		
SW	L	ØD
22	54.3	23

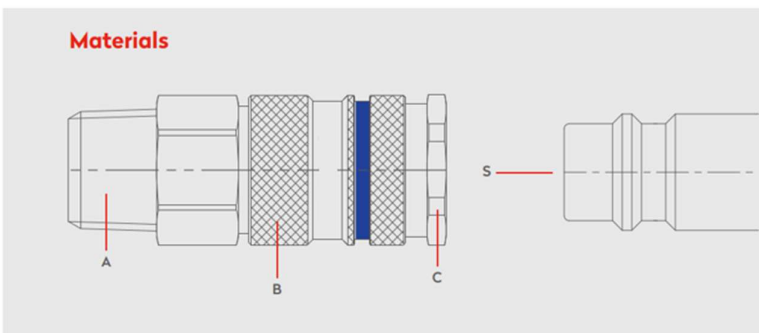

Material Code
A = Brass Nickel Plated
B = Steel Nickel Plated
C = Brass Nickel Plated
S = Steel Nickel Plated

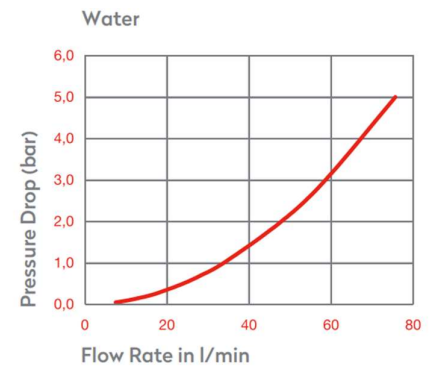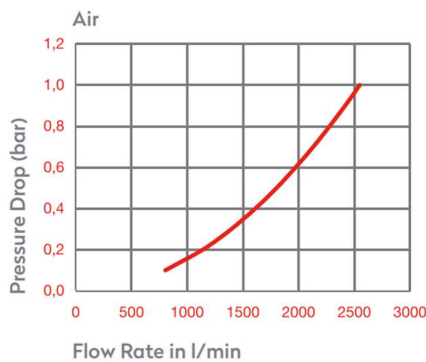

Series 25 Quick Connect Couplings

	0 - 35 bar (0-508 PSI)		-20° to +100°C (NBR) -4° to +212°F	Shut Off Type	
	OM 250 - 00500 OM 100 - 01000 025GCOOM	FLOW	1800 lt/min	DN	7.8 mm