

**ZERO-RESET click-type torque wrench with push-through ratchet, for right-/left-hand tightening, torque accuracy:  $\pm 3\%$**

**UNI EN ISO 6789**

The wrench that does not require releasing tension after use. 100% Italian-made, it is ideal for controlled tightening of screws/bolts.

**ZERO-RESET TECHNOLOGY:** Based on higher-performance materials and improved heat treatment of both the spring and the component parts of the adjustment system, the wrench no longer requires releasing tension after use.

**EASY SETTINGS:** The graduated vernier scale allows minimum interval fractions to be set up (in tenths of Nm).

**IMPROVED VISIBILITY:** Double graduation in Nm for clearer, simpler torque visibility and easy, prompt settings.


**PUSH-THROUGH RATCHET:** 72 tooth mechanism, for quick, accurate wrench operation, ensuring a take-up angle of no more than 5°.

**BI-MATERIAL HANDLE:** Ergonomic handle, for a safe, comfortable hold. Made from materials resistant to fuel, oil and industrial liquids.

**TORQUE LOCKING PUSH-PULL SYSTEM:** Lock/release knob with high-visibility red ring in released position. Torque is set by rotating the handle.

**CLICK MECHANISM:** The mechanical click can be heard and touched.

**100% ITALIAN-MADE:** Entirely designed and manufactured in Italy, assembled, tested and certified at Beta's Dynalab, at our headquarters in Sovico, which translates into top-quality torque wrenches.

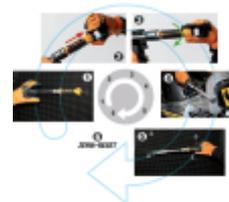

		art.
	006670720	667/20
	006670730	667/30
	006670740	667/40