




Save as PDF

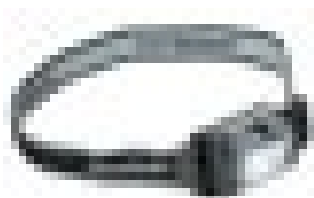

HeadsUp Lite™ 2610 LED Zone 0 Flashlight



The 2610 provides hands-free light where you need it, when you need it. A dual mode button activates all 3 LEDs for full brightness, or just 1 to extend battery life. The adjustable cloth strap fits comfortably and securely on your head, while the rubber strap grips tightly to hard hats and helmets. Both are included, as well as 3 AAA alkaline cells. The HeadsUp Lite 2610 is ideal for reading maps or light duties around the campsite as well as for work. Certified to ATEX safe for use in hazardous Zone 1 (Category 2) locations.



Materials

HeadsUp Lite™ 2610 LED Zone 0 Flashlight ANSI FL1 Specifications

LICHTBRON	Hoog LED
BATTERIJEN	3 AAA Alkaline (Included)
LAADDUUR	N/A
VOLTAGE	4.5
LANGTE	3.8 cm (1.49")
GEWICHT MET BATTERIJEN	0.13 kg (4.5 oz.)
GEWICHT ZONDER BATTERIJEN	0.05 kg (1.9 oz.)

Behuizing	Lens	Afwerking	Schakelaartype
Polycarbonate	Polycarbonate	N/A	Push button On/Off switch

Clip	Contact, veer en houder	O-ring	Nachtvisiefilm
N/A	Stainless Steel and Brass Nickel Plate	Ethylene Propylene	N/A

Configuratie

Cat. nr.	Beschrijving
2610Z0	HeadsUp Lite™ 2610 LED Zone 0 Flashlight

HeadsUp Lite™ 2610 LED Zone 0 Flashlight Accessoires

Er zijn momenteel geen accessoires beschikbaar voor dit product.

LIJCHTOPBRENGST

GEbruiksDUUR (uur/min)

LIJCHTRAALAFSTAND (meter)

MAXIMALE STRAALINTENSITEIT

FL1 STANDARD	Hoog	Laag
	19h	
	28m	19 m.
	194cd	91cd

Certificaten

CE Ex - II 1 G Ex ia IIC T4 Ga
Certificate: ITS09ATEX26185X