


544005 DGSL-20-10-PA Mini slide - Series: All

DGSL-20-10-PA/P1A/EA/Y11

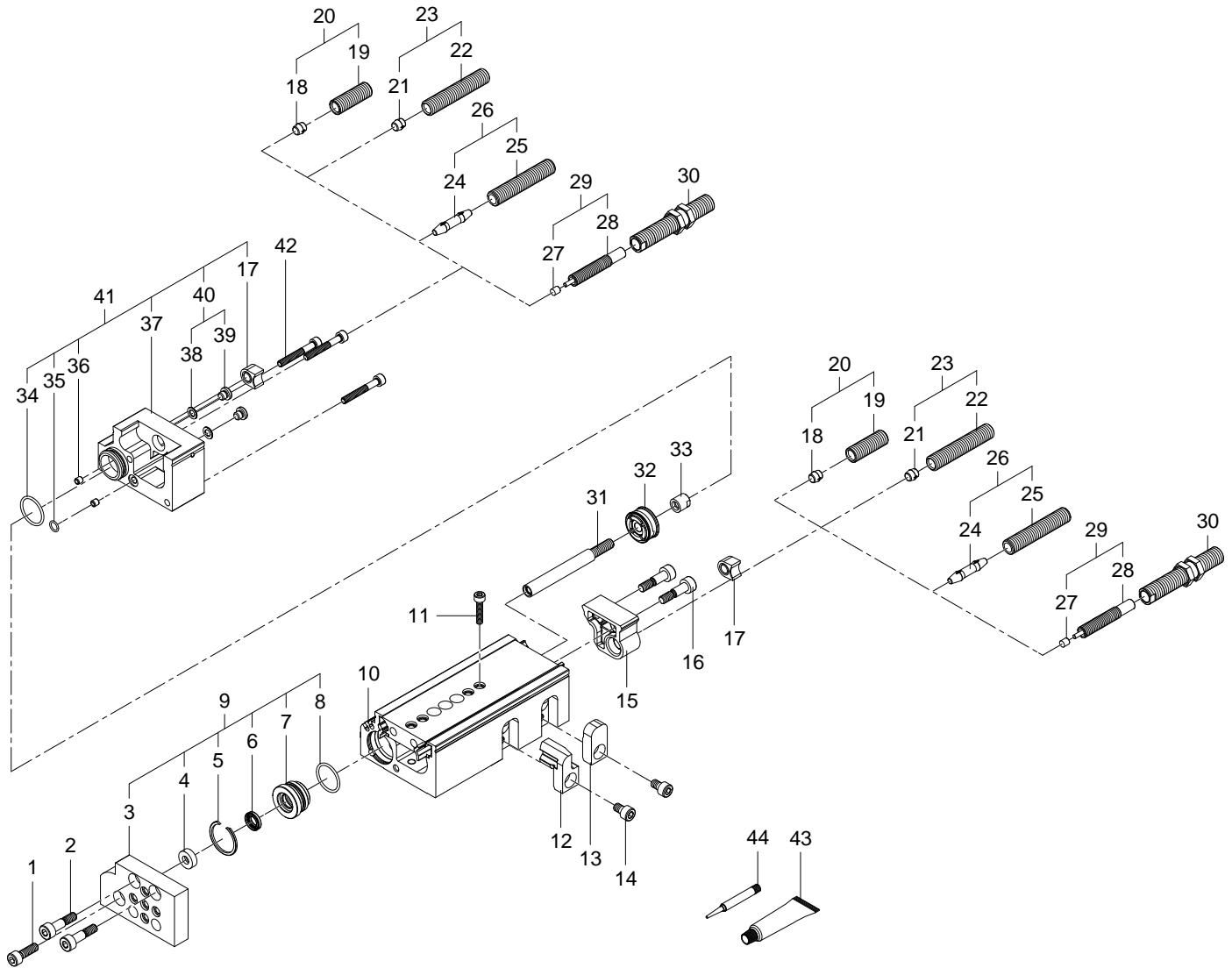

544005 DGSL-20-10-PA Mini slide - Series: All

DGSL-20-10-PA/P1A/EA/Y11

Pos.	Part no.	Type	Note	Qty.	Unit
A	713749	DGSL-20-...- Set of wearing parts	Spare parts: 5, 6, 8, 11, 18, 21, 24, 27, 32, 33, 34, 35, 38, 43, 44	1	PC
1		ISO 4762-M5X25-10.9 Socket head screw	Not available Tightening torque 9 Nm / 6.6 lbf ft	1	PC
2	696370	DGSL-16 Shaft screw	Tightening torque 7 Nm / 5.2 lbf ft	2	PC
3		DGSL-20 Yoke plate	Not available separately, see position 9 Glue with Loctite 401, adhesion surface area must free of oil and grease Warning! Disassembly requires recalibration.	1	PC
4		DGST-25 Centring sleeve	Not available separately, see position 9 Glue with Loctite 401, adhesion surface area must free of oil and grease Warning! Disassembly requires recalibration.	1	PC
5	324326	SB-26 Circlip		1	PC
6		WIFC1-10X14X3,7-NBR Wiper seal	Not available separately, see position 9+999 Grease using during assembly. See position 43	1	PC
7		DGSL-20 Bearing cap	Not available separately, see position 9 Grease using during assembly. See position 43	1	PC
8		B-22X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position 9+999 Grease using during assembly. See position 43	1	PC
9	8197199	DGSL-20 Set of components		1	PC
10		DGSL-20-10 Guide module	Not available	1	PC
11	200200	ISO 4762-M6X45-10.9 Socket head screw		1	PC
12	686788	DGSL-20 Stop		1	PC
13	686804	DGSL-20 Covering		1	PC
14		ISO 14579-M6X12-10.9 Socket head screw	Not available Tightening torque 9 Nm / 6.6 lbf ft	1	PC
15	684375	DGSL-20 Moment compensator		1	PC
16		ISO 4762-M5X25-10.9 Socket head screw	Not available Tightening torque 7 Nm / 5.2 lbf ft	2	PC
17	699257	DGSL-20 Clamping component	Use locking compound. See position 44	2	PC
18	371076	9,9X10,0 Buffer element		2	PC
19		DYEF-S-M14-Y1 adjustment sleeve	Not available separately, see position 20	1	PC
20	1153017	DYEF-S-M14-Y1 Shock absorber	shock absorber -E	2	PC
21	371076	9,9X10,0 Buffer element		2	PC
22		DGSL-20-P adjustment sleeve	Not available separately, see position 23	1	PC
23	1179863	DYEF-M14-Y1 Shock absorber	shock absorber -P	2	PC
24	683974	DGSL-12/16/20-PFJ Buffer		2	PC

Pos.	Part no.	Type	Note	Qty.	Unit
25		DGSL-20-P1 adjustment sleeve	Not available separately, see position 26	1	PC
26	548376	DYEF-M14-Y1F Shock absorber	shock absorber -P1	2	PC
27	705571	DYSC/W-10-. Buffer		1	PC
28		DYSW-8-14-Y1F Shock absorber	Not available separately, see position 29	1	PC
29	548073	DYSW-8-14-Y1F Shock absorber	Attention, please order position 30 as well shock absorber -Y11	2	PC
30	1165488	DAYH-8 reducing sleeve	Attention, please order position 29 as well shock absorber -Y11	2	PC
31	690027	IRA-10-S0056,3-B Piston rod	Glue with Loctite 401, adhesion surface area must free of oil and grease Warning! Disassembly requires recalibration.	1	PC
32		BA-K10D-025-A Complete piston	Not available separately, see position A Grease using during assembly. See position 43	1	PC
33	709442	DSNU-25 Nut	Tightening torque 7 Nm / 5.2 lbf ft Use locking compound. See position 44	1	PC
34		B-22X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 43	1	PC
35		B-9X1-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 43	1	PC
36		DGSL-20 Flow control plate	Not available separately, see position 41	2	PC
37		DGSL-20 Connection cap	Not available separately, see position 41	1	PC
38		OK-1/8 Sealing ring	Not available separately, see position A	1	PC
39		DIN 908-G1/8-ST Plug screw	Not available separately, see position 40 Tightening torque 2 Nm / 1.5 lbf ft	1	PC
40	712006	B-1/8-OK Blanking plug		2	PC
41	714233	DGSL-20-...-ET Connection cover module		1	PC
42		ISO 4762-M5X40-10.9 Socket head screw	Not available Tightening torque 2.9 Nm / 2.1 lbf ft Use locking compound. See position 44	3	PC
43	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		1	PC
44	8181256	CYBERBOND TM44 TB1ML Adhesive bonding agent		1	PC