


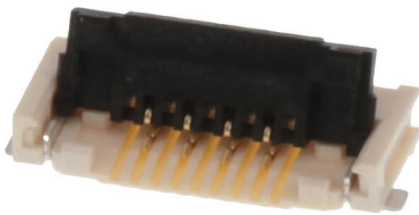

**Part Number :** [2005280181](#)  
**Product Description :** Easy-On FFC/FPC Connector,  
1.00mm Pitch, FD19 Series, Right-Angle, Bottom  
Contact, 1.90mm Height, 18 Circuits, 150°C Operating  
Temperature, Gold over Nickel Plating  
**Series Number :** 200528  
**Status :** Active  
**Product Category :** FFC / FPC Connectors



## Documents & Resources

### Drawings

[2005280181 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

### Specifications

[2005289200-200.pdf](#)

[2005280001-PS-000.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                           |
|--------------------|-----------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Compliant with Exemption 44; 34; 33                                                                       |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                              |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                                            |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024)                                                            |
| EU RoHS            | Compliant per EU 2015/863                                                                                 |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

---

## Part Details

### General

|              |                                                                                                                                                                      |
|--------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                                                               |
| Category     | FFC / FPC Connectors                                                                                                                                                 |
| Series       | FD19                                                                                                                                                                 |
| Description  | Easy-On FFC/FPC Connector, 1.00mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 18 Circuits, 150°C Operating Temperature, Gold over Nickel Plating |
| Comments     | Black Actuator                                                                                                                                                       |
| Product Name | Easy-On                                                                                                                                                              |
| UPC          | 191128824958                                                                                                                                                         |

### Electrical

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 1.0A |
| Voltage - Maximum             | 125V |

### Physical

|                   |            |
|-------------------|------------|
| Actuator Type     | Front Flip |
| Circuits (Loaded) | 18         |
| Color - Resin     | Beige      |

|                                |                        |
|--------------------------------|------------------------|
| Contact Position               | Bottom                 |
| Durability (mating cycles max) | 20                     |
| Mated Height                   | 1.90mm                 |
| Material - Metal               | Copper Alloy           |
| Material - Plating Mating      | Gold                   |
| Material - Plating Termination | Gold                   |
| Material - Resin               | Liquid Crystal Polymer |
| Net Weight                     | 229.045/mg             |
| Orientation                    | Right Angle            |
| Packaging Type                 | Embossed Tape on Reel  |
| PCB Locator                    | No                     |
| PCB Mounting                   | Surface Mount          |
| PCB Retention                  | Yes                    |
| Pitch - Mating Interface       | 1.00mm                 |
| Pitch - Termination Interface  | 1.00mm                 |
| Plating min - Mating           | 0.051µm                |
| Plating min - Termination      | 0.051µm                |
| Polarized to PCB               | Yes                    |
| Stackable                      | No                     |
| Temperature Range - Operating  | -40° to +150°C         |
| Wire/Cable Type                | FFC/FPC                |