


Geberit Mapress Carbon Steel bend with plain end (FKM, blue)



Example image

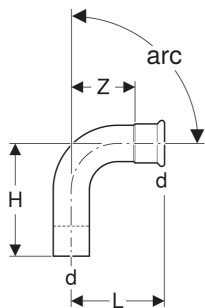

APPLICATION PURPOSES

- For district heating water ≤ 140 °C
- For thermal media (solar)
- For mineral and lubricating oil
- For motor fuels (e.g. diesel)
- For compressed air (oil purity class 3–4)
- For solar technology, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Outside zinc-plated
- Seal ring made of FKM, blue
- Pressing socket with black protection plug

TECHNICAL DATA

Product material Non-alloy steel 1.0034 E195 (EN 10305)

INFO

- Dimension changes of individual articles as per table will be completed by end of May 2026

Art. no.	DN	d, ø mm	arc °	L cm	H cm	Z cm
51242	12	15	45	3.6	4.5	1.6
51243	15	18	45	3.7	4.2	1.7
51244	20	22	45	4.2	5.2	2.1
51245	25	28	45	4.8	5.6	2.5

Art. no.	DN	d _g mm	arc °	L cm	H cm	Z cm
51246	32	35	45	4.3	5.3	1.7
51247	40	42	45	5.1	6.1	2.1
51248	50	54	45	6.2	7.3	2.7
51251	65	76.1	45	10.3	11.1	5
51252	80	88.9	45	11.7	12.8	5.7
51253	100	108	45	14.3	15.8	6.8
51312	12	15	90	4.9	5.9	2.9
51313	15	18	90	4.2	5.1	2.2
51314	20	22	90	6.1	7	4
51315	25	28	90	7.2	7.9	4.9
51316	32	35	90	6.8	7.4	4.2
51317	40	42	90	8	8.8	5
51318	50	54	90	10	10.8	6.5

Art. no.	DN	d _ø mm	arc °	L cm	H cm	Z cm
51321	65	76.1	90	15.7	16.7	10.4
51322	80	88.9	90	18.4	19.5	12.4
51323	100	108	90	22.6	24.1	15.1