


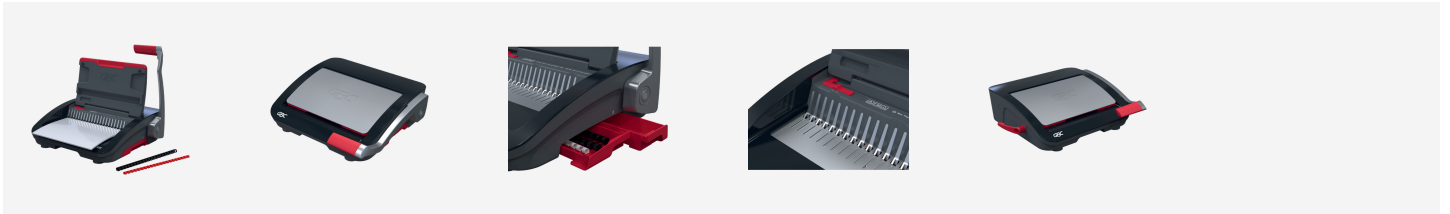

## GBC CombBind® CB20 Manual Binding Machine

The CombBind® CB20 is a reliable and compact manual comb binder designed for shared use in office and school environments with medium volume demands. It can punch through up to 20 sheets of 80gsm paper and efficiently bind up to 240 sheets at a time using 28mm spines. Its lightweight, space-saving design makes it ideal for use anywhere, anytime, and easy to store when not in use. For added convenience, it features a clippings tray for easy disposal and a storage compartment. Black and silver colour.



## Attributes

- Binds up to 240 A5/A4 sheets (80gsm) at a time using a 28mm comb.
- Punches up to 20 sheets at a time (80gsm)
- Versatile binding: easily bind A5 documents with A5 combs and A4 portrait pages with A4 combs.
- Manual single-handle punch for an effortless and smooth binding experience.
- Side margin adjustment for precise alignment and consistent binding results.
- Fixed margin depth for consistent and high quality binding.
- Non-slip rubber feet for stable and secure placement.
- Convenient clippings tray and a built-in storage compartment for added organisation.
- Lightweight and compact design for easy portability and convenient storage.

## Specifications

|                                     |                      |
|-------------------------------------|----------------------|
| Number                              | 4410062              |
| Colour                              | black                |
| Material                            | Plastic              |
| Dimensions (W x H x D)              | 497 x 402 x 394 mm   |
| For Format                          | A4/A5                |
| Max. Binding Width (mm)             | 297                  |
| Operation Mode                      | Manual Single Handle |
| Max. Binding Capacity (70gsm paper) | 240                  |
| Punch Capacity (70gsm paper)        | 23                   |
| Punch Capacity (80gsm paper)        | 20                   |
| Punch Capacity (Clear Film 0,2 mm)  | 2                    |
| No. of Punches                      | 21                   |
| Electric punching                   | No                   |
| Spine size selector                 | No                   |
| Max. Comb Diameter (mm)             | 28                   |
| Waste tray                          | Yes                  |
| Suitable for                        | Comb Punch and Bind  |
| Weight                              | 6600 g               |
| Packing unit                        | 1                    |
| Pallet quantity                     | 16                   |
| Minimum order quantity              | 1                    |
| EAN code                            | 5028252644471        |