


Masking frame 3VA13 (400 A), 3VA14 (630 A), 3VA23 (400 A), 3VA24 (630 A), 4-pole, fixed-mounted, plug-in socket, drive: direct, front-mounted rotary operator motorized operating mechanism, RCD: without, H: 250 mm W: 600 mm

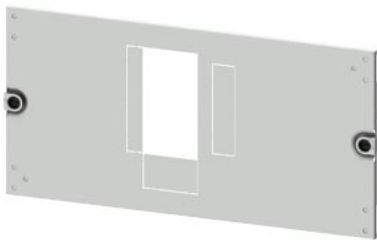

Model	
product brand name	SIVACON S4
design of the surface	powder-coated
net weight	1.2 kg
height	250 mm
width	600 mm
depth	10 mm
installation width for cabinet installation	600 mm
mounting height for device equipment can be used	250 mm
material	sheet-steel
reference code according to IEC 81346-2	UC

Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Confirmation](#)

Environment

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ2025-6BA23>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8PQ2025-6BA23>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ2025-6BA23
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

